
 

 
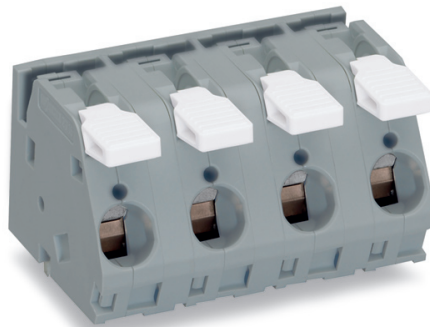
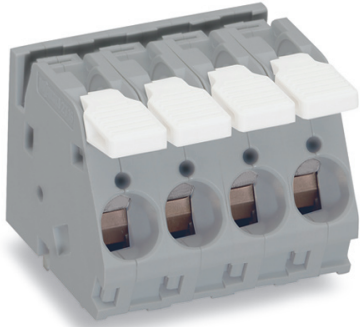




















Terminal Strips 16 mm²/AWG 6 with Jumper Slot, Pin Spacings 10 mm/0.394 in and 15 mm/0.591 in; Series 2716


CAGE CLAMP®

Pin spacing 10 mm / 0.394 in 1.5 – 16 mm ² AWG 16 – 6 250 V/4 kV/3; 76 A 300 V, 55 A  500 V/4 kV/2; 76 A  12 – 13 mm / 0.49 in	Pin spacing 15 mm / 0.591 in 1.5 – 16 mm ² AWG 16 – 6 630 V/8 kV/3; 76 A 600 V, 65 A  1000 V/8 kV/2; 76 A  12 – 13 mm / 0.49 in	
------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	--

 


No. of poles	Item no.	Pack.-unit			
Terminal strips, gray, with actuating lever, with jumper slot			Terminal strips, gray, with actuating lever, with jumper slot		
2	2716-152		2	2716-252	
3	2716-153		3	2716-253	
4	2716-154		4	2716-254	
5	2716-155		5	2716-255	
6	2716-156		6	2716-256	
7	2716-157		7	2716-257	
8	2716-158		8	2716-258	
Other numbers of poles and pin spacings on request Additional item nos. for colored terminal blocks:			For other lengths, please contact factory Additional item nos. for colored terminal blocks:		
blue	... /000-006 		blue	... /000-006 	
light gray	... /000-009 		light gray	... /000-009 	
green-yellow	... /000-016 		green-yellow	... /000-016 	
light green	... /000-017 		light green	... /000-017 	
 Comb type jumper bar 1 to 3 745-682 200 (4x50)			 Comb type jumper bar 1 to 3 745-631 200 (4x50)		
 2-way 745-582 200 (4x50)			 2-way 745-632 200 (4x50)		
 3-way 745-583 200 (4x50)			 3-way 745-633 200 (4x50)		
 4-way 745-584 200 (4x50)			 4-way 745-634 200 (4x50)		
 5-way 745-585 200 (4x50)			 5-way 745-635 200 (4x50)		

Dimensions (in mm)

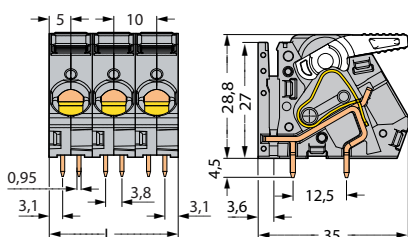

Diameter of drilled hole: 1.6^{+0.1} mm
 L = (No. of poles x pin spacing) + 1.5 mm

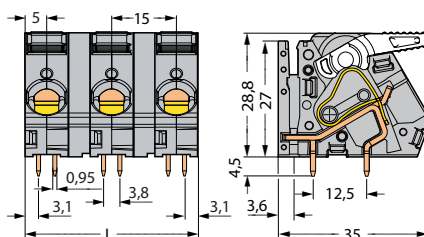

Diameter of drilled hole: 1.6^{+0.1} mm
 L = (No. of poles x pin spacing) + 1.5 mm