


Item no.: 288-312
 Product description: SWITCHING RELAY MODULE RELAY DIRECT SOLDERED
 RELAY WITH 2 CHANGEOVER CONTACTS (2u)

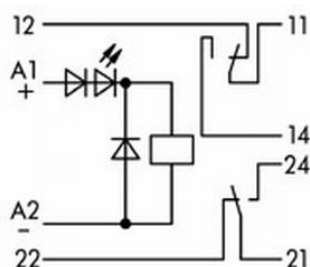

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

Product group	6 (Electronics)
Coil voltage DC	24 V
Contact material	AgNi 0.15 + HV
max. switching voltage	AC/DC 250 V
max. make current	4 s 14 A
max. break current	8 A
max. continuous current	6 A
max. switching power (resistive) VA	1500 VA
max. switching power (resistive) W	100 W
Pull-in power	261 mW
Operating power	533 mW
Pull-in time (typ)	8 ms
Drop-out time (typ)	0 ms
Bounce time (typ)	2 ms
Dielectric strength contact / coil (kV)	2.5 kV
Nominal voltage acc. to VDE 0110/1.89	Safety data
Mechanical life	30 x 10 ⁶ switching operations
Mechanical life at max. resistive load AC	1 x 10 ⁵ switching operations
Ambient operating temperature	-25 °C ... +40 °C
Current consumption (Un) (Coil 20 °C)	21.8 mA

Cross section [mm²]
Cross section [AWG]

0.08 - 2.5 mm²
28 - 12 AWG



Connection method	CAGE CLAMP® CONNECTION
Weight	45.4 g
Color	gray
Height	48 mm
Height	1.89 in
Width	22.5 mm
Width	0.886 in
Depth	85 mm
Depth	3.346 in
Strip length from	5 mm
Strip length to	6 mm
Strip length	0.22 in
Mounting	TS 35

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected