


Item no.: 713-1103
 Product description: FEMALE CONNECTOR 3X2 POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED AGAINST MISMATING

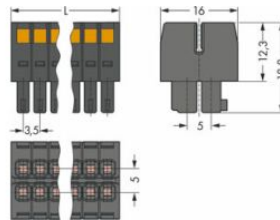

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Weight	5.78 g
Color	black
No. of connection Points	6
No. of potentials	6
pole count	6
Height	18.8 mm
Height	0.74 in
Width	12 mm
Width	0.472 in
Depth	16 mm
Depth	0.63 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	250 V

Measured shock voltage
Current intensity EN
Connection method

2.5 kV
10 A
CAGE CLAMP® CONNECTION



Cross section [mm ²]	0.08 - 1.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 1.5 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [AWG]	28 - 16 AWG
Strip length from	6 mm
Strip length to	7 mm
Material group	II
Customs Tariff No.	85366990
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected