


Item no.: 713-1108/107-000  
 Product description: FEMALE CONNECTOR WITH SCREW FLANGES 8X2 POLE  
 PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED  
 AGAINST MISMATING

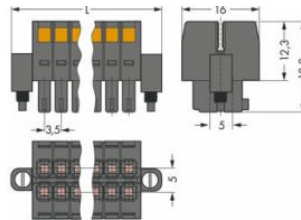

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Weight	0 g
Color	black
No. of connection Points	16
No. of potentials	16
pole count	16
Height	18.75 mm
Height	0.738 in
Width	38.1 mm
Width	1.5 in
Depth	16 mm
Depth	0.63 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2

Measured voltage EN	250 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Connection method	CAGE CLAMP® CONNECTION



Cross section [mm <sup>2</sup> ]	0.08 - 1.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1 mm <sup>2</sup>
Cross section [AWG]	28 - 16 AWG
Strip length from	6 mm
Strip length to	7 mm
Material group	II
Customs Tariff No.	85366990
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected