


Item no.: 713-1110
 Product description: FEMALE CONNECTOR 10X2 POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED AGAINST MISMATING

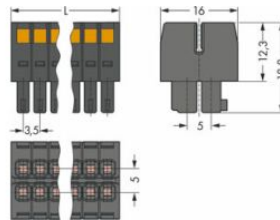

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Weight	10.21 g
Color	black
No. of connection Points	20
No. of potentials	20
pole count	20
Height	18.8 mm
Height	0.74 in
Width	36.5 mm
Width	1.437 in
Depth	16 mm
Depth	0.63 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	250 V

Measured shock voltage
Current intensity EN
Connection method

2.5 kV
10 A
CAGE CLAMP® CONNECTION



Cross section [mm ²]	0.08 - 1.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 1.5 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [AWG]	28 - 16 AWG
Strip length from	6 mm
Strip length to	7 mm
Material group	II
Customs Tariff No.	85366990
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected