


Item no.: 713-1428/107-000
 Product description: HEADER RIGHT ANGLE SOLDER PIN 0.8x0.8 MM 8X2 POLE WITH TREADED FLANGES PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED AGAINST MISMATING MATING DIRECTION PARALLEL TO PCB

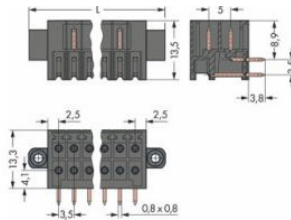

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Weight	0 g
Color	black
pole count	16
Height	13.3 mm
Height	0.524 in
Width	38.1 mm
Width	1.5 in
Depth	13.5 mm
Depth	0.531 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	250 V

Measured shock voltage	2.5 kV
Current intensity EN	10 A
Material group	I
Customs Tariff No.	85369010
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected