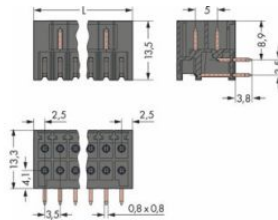
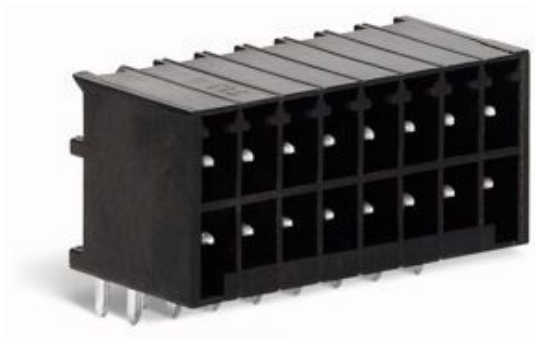

Item no.: 713-1430
Product description: HEADER RIGHT ANGLE SOLDER PIN 0.8x0.8 MM 10X2
POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED
AGAINST MISMATING MATING DIRECTION PARALLEL TO
PCB



Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Weight	5.5 g
Color	black
pole count	20
Height	13.3 mm
Height	0.524 in
Width	36.5 mm
Width	1.437 in
Depth	13.5 mm
Depth	0.531 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	250 V

Measured shock voltage	2.5 kV
Current intensity EN	10 A
Material group	I
Customs Tariff No.	85369010
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected