


Item no.: 721-103/037-000
 Product description: FEMALE CONNECTOR WITH LOCKING LEVER 3 POLE PIN
 SPACING 5 MM / 0.197 IN 100% PROTECTED AGAINST
 MISMATING WITH CODING FINGERS WITH 2 LATCHES

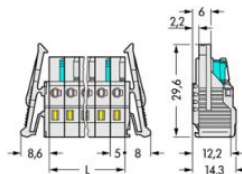

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

Product group	3 (Multi Conn. System)
Weight	7.16 g
Color	light gray
No. of connection Points	3
No. of potentials	3
pole count	3
Height	14.3 mm
Height	0.563 in
Width	31.6 mm
Width	1.244 in
Depth	29.6 mm
Depth	1.165 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2

Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/032-000	Strain relief plate 11,5 mm
xxx-xxx/xxx-045	1-PE-3
xxx-xxx/xxx-047	1-2-3-4-5-...



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
721-103/037-000	ABS	04-HG469925/1-PDA	250	16	0,8-2,5
721-103/037-000	BV	11914/AO	250	16	
721-103/037-000	CCA	5764	250	16	0,08-2,5
721-103/037-000	CSA	154112-1466354	300	15	28-12
721-103/037-000	DNV	E-9218	250	16	0,8-2,5
721-103/037-000	GL	17296-00HH	250	16	
721-103/037-000	KEMA	2083746.02	250	16	0,08-2,5
721-103/037-000	KR	HMB05880-EL003	250/400	12/16	2,5
721-103/037-000	LR	96/20035	250	16	0,8-2,5
721-103/037-000	RMR	11130002	250	16	0,8-2,5
721-103/037-000	UR	E45171	600	20	28-12
721-103/037-000	UR	E45172	300/150/300	15/15/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected