


Item no.: 721-432/001-000
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN 2 POLE PIN SPACING 5 MM / 0.197 IN 100% PROTECTED AGAINST MISMATING WITHOUT PRECEDING GROUND CONTACT WITH CLOSED END MATING DIRECTION PARALLEL TO PCB

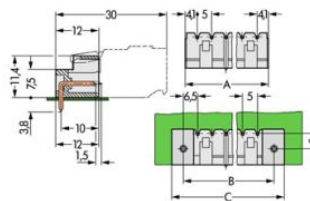

Produkt kann von Bild abweichen / product may differ

Packing unit 200 4*50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	0.88 g
Color	light gray
pole count	2
Height	11.4 mm
Height	0.449 in
Width	13.2 mm
Width	0.52 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A

Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
721-432/001-000	ABS	04-HG469925/1-PDA	250	12	
721-432/001-000	BV	11915/A0	250	12	
721-432/001-000	CCA	5764	250	12	1x11
721-432/001-000	CSA	154112-1466354	300	10	
721-432/001-000	DNV	E-9218	250	12	
721-432/001-000	GL	17296-00HH	250	12	
721-432/001-000	KEMA	2083746.02	250	12	1x11
721-432/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
721-432/001-000	LR	96/20035	250	12	
721-432/001-000	RMR	11130002	250	12	
721-432/001-000	UR	E45171	600	20	
721-432/001-000	UR	E45172	300	10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected