


Item no.: 721-606/019-000  
 Product description: MALE CONNECTOR WITH FIXING FLANGE 6 POLE PIN  
 SPACING 5 MM / 0.197 IN 100% PROTECTED AGAINST  
 MISMATING WITHOUT PRECEDING GROUND CONTACT  
 FOR SCREW OR SIMILAR MOUNTING TYPES FOR  
 PARALLEL OR PERPENDICULAR MOUNTING

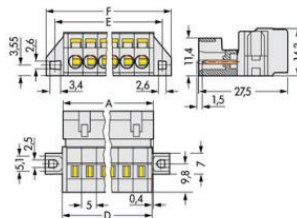

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	10.43 g
Color	light gray
No. of connection Points	6
No. of potentials	6
pole count	6
Height	14.3 mm
Height	0.563 in
Width	44.8 mm
Width	1.764 in
Depth	27.5 mm
Depth	1.083 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V

Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 2.5 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/034-000	Strain relief plate 30 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
721-606/019-000	ABS	04-HG469925/1-PDA	250	12	0,08-2,5
721-606/019-000	BV	11915/A0	250	12	
721-606/019-000	CCA	5764	250	12	0,08-2,5
721-606/019-000	DNV	E-9218	250	12	0,08-2,5
721-606/019-000	GL	17296-00HH	250	12	
721-606/019-000	KEMA	2083746.02	250	12	0,08-2,5
721-606/019-000	LR	96/20035	250	12	0,08-2,5
721-606/019-000	RMR	11130002	250	12	0,08-2,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected