


Item no.: 722-202/026-000
 Product description: ANGLED FEMALE PLUG 2 POLE PIN SPACING 5 MM / 0.197 IN 100% PROTECTED AGAINST MISMATING WITH CODING FINGERS CONDUCTOR EXIT SAME DIRECTION AS LATCHES WITH MOUNTING FEET

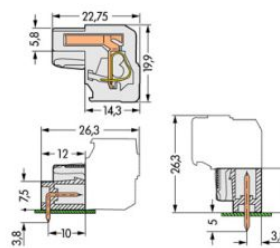

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Product group	3 (Multi Conn. System)
Weight	3.98 g
Color	light gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	19.9 mm
Height	0.783 in
Width	12.4 mm
Width	0.488 in
Depth	22.75 mm
Depth	0.896 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	14 A

Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	14 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/032-000	Strain relief plate 11,5 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
722-202/026-000	CSA	154112-1466354	300	10	0,6x1
722-202/026-000	KEMA	2083746.02	250	12	0,08-2,5
722-202/026-000	UR	E45171	600	10	28-12
722-202/026-000	UR	E45172	300/150/300	15/15/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected