


Item no.: 733-110
 Product description: FEMALE CONNECTOR WITH CODING FINGERS 10 POLE
 PIN SPACING 2.5 MM / 0.098 IN 100% PROTECTED
 AGAINST MISMATING

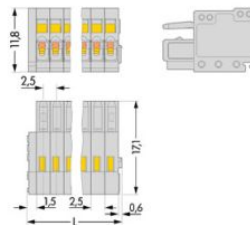

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Weight	4.34 g
Color	light gray
No. of connection Points	10
No. of potentials	10
pole count	10
Height	11.8 mm
Height	0.465 in
Width	27.5 mm
Width	1.083 in
Depth	17.1 mm
Depth	0.673 in
Pin spacing from	2.5 mm
Pin spacing from	0.098 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	6 A
Pollution degree	2
Measured voltage EN	320 V

Measured shock voltage
Current intensity EN
Connection method

2.5 kV
6 A
CAGE CLAMP® CONNECTION



Cross section [mm ²]	0.08 - 0.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 0.5 mm ²
Wiring method	fine-stranded
Cross section [mm ²]	0.25 - 0.34 mm ²
Wiring method	fine-stranded (with ferrule and plastic collar)
Cross section [mm ²]	0.25 - 0.34 mm ²
Wiring method	fine-stranded (with ferrule, without plastic collar)
Cross section [AWG]	28 - 20 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
Contact surface	tin-plated
xxx-xxx/033-000	Strain relief plate 12,5 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
733-110	ABS	04-HG469925/1-PDA	250	4	0,8-0,5
733-110	BV	11915/A0	250	4	0,8-0,5
733-110	CCA	NL5640	250	4	0,8-0,5
733-110	CSA	154112-1465035	150	4	28-20
733-110	DNV	E-9218	250	4	0,8-0,5
733-110	GL	17296-00HH	250	4	0,8-0,5
733-110	LR	96/20035	250	6	0,8-0,5
733-110	RMR	11130002	250	4	0,8-0,5
733-110	UR	E45171	250	4	28-20
733-110	UR	E45172	150	4	28-20

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected