




Product Number: 733-204

MALE CONNECTOR 4 POLE PIN SPACING 2.5 MM / 0.098 IN 100% PROTECTED AGAINST MISMATING

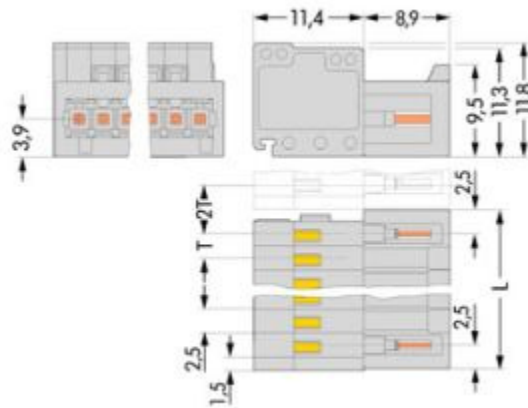

T = 2,5 mm
 = (No.of poles + 1) x pin spacing

Packing unit 200 pieces

RoHS compliant

Weight	2.17 g
Color	light gray
No. of connection Points	4
No. of potentials	4
pole count	4
Height	11.8 mm
Height	0.465 in
Width	12.5 mm
Width	0.492 in
Depth	20.3 mm
Depth	0.799 in
Pin spacing from	2.5 mm
Pin spacing from	0.098 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV

Current intensity EN	6 A
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	2.5 kV
Current intensity EN	6 A
Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 0.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 0.5 mm ²
Wiring method	fine-stranded
Cross section [mm ²]	0.25 - 0.34 mm ²
Wiring method	fine-stranded (with ferrule and plastic collar)
Cross section [mm ²]	0.25 - 0.34 mm ²
Wiring method	fine-stranded (with ferrule, without plastic collar)
Cross section [AWG]	28 - 20 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
Contact surface	tin-plated