


Item no.: 733-332
 Product description: HEADER STRAIGHT SOLDER PIN 0.8x0.8 MM 2 POLE PIN SPACING 2.5 MM / 0.098 IN 100% PROTECTED AGAINST MISMATING MATING DIRECTION PERPENDICULAR TO PCB WITH CLOSED END

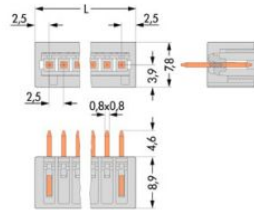

Produkt kann von Bild abweichen / product may differ

Packing unit 200 pieces

RoHS compliant

| | |
|------------------------|------------|
| Weight | 0.38 g |
| Color | light gray |
| pole count | 2 |
| Height | 8.9 mm |
| Height | 0.35 in |
| Width | 7.5 mm |
| Width | 0.295 in |
| Depth | 7.8 mm |
| Depth | 0.307 in |
| Pin spacing from | 2.5 mm |
| Pin spacing from | 0.098 in |
| Pollution degree | 2 |
| Measured voltage EN | 160 V |
| Measured shock voltage | 2.5 kV |
| Current intensity EN | 6 A |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |

| | |
|------------------------|---------------------------|
| Measured shock voltage | 2.5 kV |
| Current intensity EN | 6 A |
| Material group | I |
| Contact material | Electrolytic copper (Ecu) |
| Contact surface | tin-plated |



| Item no. | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|----------|------------------|-------------------|-------------|-------------|-----------------------------------|
| 733-332 | ABS | 04-HG469925/1-PDA | 250 | 4 | |
| 733-332 | BV | 11915/A0 | 250 | 4 | |
| 733-332 | CSA | 154112-1465035 | 150 | 4 | 28-20 |
| 733-332 | DNV | E-9218 | 250 | 4 | |
| 733-332 | GL | 17296-00HH | 250 | 4 | |
| 733-332 | KEMA | 2077592.01 | 250 | 4 | |
| 733-332 | LR | 96/20035 | 250 | 6 | |
| 733-332 | RMR | 11130002 | 250 | 4 | |
| 733-332 | UR | E45171 | 250 | 4 | |
| 733-332 | UR | E45172 | 150 | 4 | 28-20 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected