


Item no.: 734-136  
 Product description: HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN  
 6 POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED  
 AGAINST MISMATING WITH CLOSED END MATING  
 DIRECTION PERPENDICULAR TO PCB

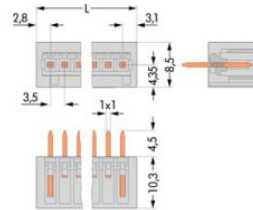

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Product group	3 (Multi Conn. System)
Weight	1.516 g
Color	light gray
pole count	6
Height	10.3 mm
Height	0.406 in
Width	23.4 mm
Width	0.921 in
Depth	8.5 mm
Depth	0.335 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	320 V

Measured shock voltage	2.5 kV
Current intensity EN	10 A
Material group	I
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
734-136	ABS	04-HG469925/1-PDA	250	10	0,5-1,5
734-136	BV	11915/A0	250	10	0,5-1,5
734-136	CCA	NL5641	250	10	0,5-1,5
734-136	CSA	154112-1465035	300	10	28-14
734-136	DNV	E-9218	250	10	0,5-1,5
734-136	GL	17296-00HH	250	10	0,5-1,5
734-136	KEMA	2077592.02	250	10	0,5-1,5
734-136	LR	96/20035	250	10	0,5-1,5
734-136	RMR	11130002	250	10	0,5-1,5
734-136	UR	E45171	250	10	
734-136	UR	E45172	300	10/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected