


Item no.: 734-168
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN 8 POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED AGAINST MISMATING WITH CLOSED END MATING DIRECTION PARALLEL TO PCB

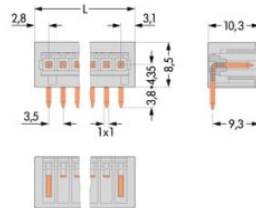

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Product group	3 (Multi Conn. System)
Weight	2.172 g
Color	light gray
pole count	8
Height	8.5 mm
Height	0.335 in
Width	30.4 mm
Width	1.197 in
Depth	10.3 mm
Depth	0.406 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	320 V

Measured shock voltage	2.5 kV
Current intensity EN	10 A
Material group	I
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
734-168	ABS	04-HG469925/1-PDA	250	10	0,5-1,5
734-168	BV	11915/A0	250	10	0,5-1,5
734-168	CCA	NL5641	250	10	0,5-1,5
734-168	CSA	154112-1465035	300	10	28-14
734-168	DNV	E-9218	250	10	0,5-1,5
734-168	GL	17296-00HH	250	10	0,5-1,5
734-168	KEMA	2077592.02	250	10	0,5-1,5
734-168	LR	96/20035	250	10	0,5-1,5
734-168	RMR	11130002	250	10	0,5-1,5
734-168	UR	E45171	250	10	28-14
734-168	UR	E45172	300	10/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected