
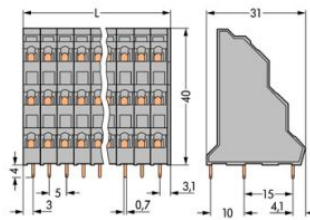


Item no.: 737-108  
 Product description: TRIPLE DECK PCB TERMINAL STRIP 3 SOLDER PINS IN LINE 8X3 POLE PIN SPACING 5 MM / 0.197 IN

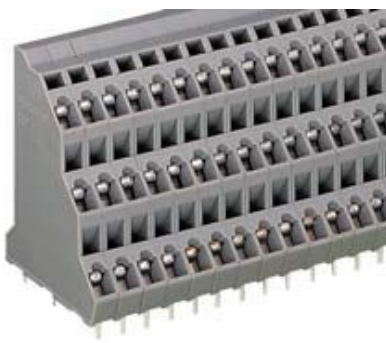

Produkt kann von Bild abweichen / product may differ

Packing unit 24 pieces

Product group	4 (Printed Circuit)
Weight	33.48 g
Color	gray
No. of connection Points	24
No. of potentials	24
pole count	8
Height	40 mm
Height	1.57 in
Width	41 mm
Width	1.614 in
Depth	31 mm
Depth	1.22 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	21 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage  
Current intensity EN

4 kV  
21 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 2.5 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
737-108	ABS	04-HG469925/1-PDA	250	12	0,5-2,5
737-108	BV	11915/A0	250	12	0,5-2,5
737-108	CCA	NL6267	250	12	0,5-2,5
737-108	CSA	18677-26	300	10	28-12
737-108	DNV	E-9215	250	12	0,5-2,5
737-108	GL	17296-00HH	250	12	0,5-2,5
737-108	KEMA	2110204.07	250	12	0,5-2,5
737-108	RMR	11130002	250	12	0,5-2,5
737-108	UR	E45172	300/300	10/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected