


Item no.: 739-105
 Product description: PCB TERMINAL STRIP 1 SOLDER PIN / POLE 5 POLE PIN
 SPACING 5 MM / 0.197 IN

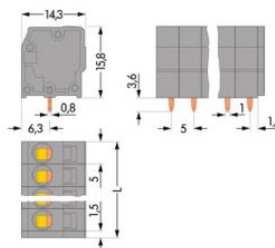

Produkt kann von Bild abweichen / product may differ

Packing unit 180 4*45 pieces

Product group	4 (Printed Circuit)
Weight	6.014 g
Color	gray
No. of connection Points	5
No. of potentials	5
pole count	5
Height	15.8 mm
Height	0.622 in
Width	26.5 mm
Width	1.043 in
Depth	14.3 mm
Depth	0.563 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	24 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage
Current intensity EN

4 kV
24 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section to [mm ²]	1.5 mm ²
Cross section to [mm ²]	2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/000-004	black
xxx-xxx/000-005	red
xxx-xxx/000-006	blue
xxx-xxx/000-014	brown
xxx-xxx/000-017	light green
xxx-xxx/000-023	green



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
739-105	CCA	DK2079	250	12	0,5-2,5
739-105	CSA	154112-1711139	300	12	28-12
739-105	RMR	11130002	250	12	0,5-2,5
739-105	UR	E45172	300/300	12/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected