


Item no.: 741-303
 Product description: FEEDTHROUGH TERMINAL STRIPS 2 SOLDER PINS / POLE 3 POLE WITH INTEGRATED PUSH BUTTONS AND TOUCH CONTACT TESTING PIN SPACING 7.5 MM / 0.295 IN

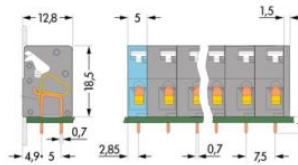

Packing unit 220 4*55 pieces

Product group	4 (Printed Circuit)
Weight	4.8 g
Color	gray
No. of connection Points	3
No. of potentials	3
pole count	3
Height	18.5 mm
Height	0.728 in
Width	21.5 mm
Width	0.846 in
Depth	12.8 mm
Depth	0.504 in
Pin spacing from	7.5 mm
Pin spacing from	0.295 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	6 kV
Current intensity EN	16 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
741-303	ABS	04-HG469925/1-PDA	400	16	0,08-2,5
741-303	BV	11915/A0	400	16	0,08-2,5
741-303	CCA	NL6251	400	24	0,08-2,5
741-303	CSA	154112-1711139	300	16	28-12
741-303	DNV	E-9215	400	16	0,08-2,5
741-303	GL	17296-00HH	400	16	0,08-2,5
741-303	KEMA	2110204.05	400	24	0,08-2,5
741-303	UR	E45172	300/300	10/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected