


Item no.: 745-1352
 Product description: PCB TERMINAL STRIP 2 SOLDER PINS / POLE 2 POLE PIN
 SPACING 10 MM / 0.394 IN with grid spacers WITHOUT
 FIXING FLANGE

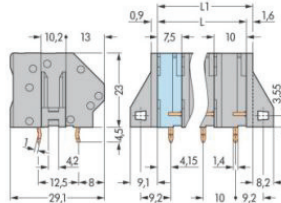

Produkt kann von Bild abweichen / product may differ

Packing unit 104 piece

RoHS compliant

Weight	11.069 g
Color	gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	23 mm
Height	0.906 in
Width	19.1 mm
Width	0.752 in
Depth	29.1 mm
Depth	1.15 in
Pin spacing from	10 mm
Pin spacing from	0.394 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	41 A
Pollution degree	2

Measured voltage EN
Measured shock voltage
Current intensity EN
Connection method

1000 V
8 kV
41 A
CAGE CLAMP® CONNECTION



Cross section [mm ²]	0.2 - 6 mm ²
Wiring method	solid
Cross section [mm ²]	0.2 - 6 mm ²
Cross section [mm ²]	0.25 - 4 mm ²
Cross section [mm ²]	0.25 - 4 mm ²
Cross section [AWG]	24 - 10 AWG
Strip length from	11 mm
Strip length to	12 mm
Material group	I
Customs Tariff No.	85369010
Country of Origin	Schweiz
xxx-xxx/000-006	blue
xxx-xxx/000-009	light gray
xxx-xxx/000-016	green-yellow
xxx-xxx/000-017	light green
xxx-xxx/005-000	with fixing flange
xxx-xxx/005-xxx	with fixing flange



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
745-1352	CCA	NL6296	630	41	0,02-6
745-1352	cURus	E45172	300	10	10-24
745-1352	KEMA	2097989.01	630	41	0,02-6

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected