


Item no.: 745-3254  
 Product description: PCB TERMINAL STRIP 2 SOLDER PINS / POLE 4 POLE PIN  
 SPACING 12.5 MM / 0.492 IN without jumper slot

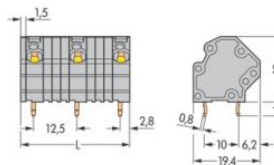

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	4 (Printed Circuit)
Weight	9.519 g
Color	gray
No. of connection Points	4
No. of potentials	4
pole count	4
Height	19 mm
Height	0.748 in
Width	44 mm
Width	1.732 in
Depth	19.4 mm
Depth	0.764 in
Pin spacing from	12.5 mm
Pin spacing from	0.492 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	32 A
Pollution degree	2

Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	32 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm²]	0.08 - 4 mm²
Wiring method	solid
Cross section [mm²]	0.08 - 4 mm²
Cross section [mm²]	0.25 - 2.5 mm²
Cross section [mm²]	0.25 - 2.5 mm²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
Customs Tariff No.	85369010
Country of Origin	Polen
xxx-xxx/000-006	blue
xxx-xxx/000-009	light gray
xxx-xxx/000-016	green-yellow
xxx-xxx/000-017	light green



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
745-3254	cURus	E45172	600	20	28-12
745-3254	KEMA	2076500.01	630	32	0,08-4

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected