


Item no.: 745-602/006-000  
 Product description: PCB TERMINAL STRIP 4 SOLDER PINS/POLE 2 POLE PIN  
 SPACING 15 MM / 0.591 IN WITHOUT FIXING FLANGE

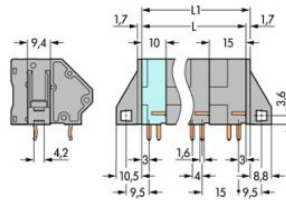

Produkt kann von Bild abweichen / product may differ

Packing unit 36 pieces

RoHS compliant

Product group	4 (Printed Circuit)
Weight	20.956 g
Color	gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	27 mm
Height	1.06 in
Width	26.7 mm
Width	1.051 in
Depth	33.4 mm
Depth	1.315 in
Pin spacing from	15 mm
Pin spacing from	0.591 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	76 A
Pollution degree	2

Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	76 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm²]	0.2 - 16 mm²
Wiring method	solid
Cross section [mm²]	0.2 - 16 mm²
Cross section [mm²]	0.25 - 10 mm²
Cross section [mm²]	0.25 - 10 mm²
Cross section [AWG]	24 - 6 AWG
Strip length from	12 mm
Strip length to	13 mm
Material group	I
xxx-xxx/000-006	blue
xxx-xxx/000-009	light gray
xxx-xxx/000-016	green-yellow
xxx-xxx/000-017	light green
xxx-xxx/000-021	light gray $\wedge$ RAL 7035
xxx-xxx/011-000	with fixing flange
xxx-xxx/011-xxx	with fixing flange

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected