


Item no.: 745-834
 Product description: MODULAR PCB TERMINAL BLOCK 2 SOLDER PINS / POLE
 1 POLE SUITABLE FOR EX I APPLICATIONS PIN SPACING
 7.5 MM / 0.295 IN

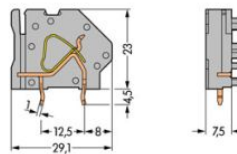

Produkt kann von Bild abweichen / product may differ

Packing unit 100 2*50 pieces

Product group	4 (Printed Circuit)
Weight	4.74 g
Color	blue
No. of connection Points	1
No. of potentials	1
pole count	1
Height	23 mm
Height	0.906 in
Width	7.5 mm
Width	0.295 in
Depth	29.1 mm
Depth	1.15 in
Pin spacing from	7.5 mm
Pin spacing from	0.295 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	41 A
Pollution degree	2

Measured voltage EN	1000 V
Measured shock voltage	6 kV
Current intensity EN	41 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.2 - 6 mm ²
Wiring method	solid
Cross section [mm ²]	0.2 - 6 mm ²
Cross section [mm ²]	0.25 - 4 mm ²
Cross section [mm ²]	0.25 - 4 mm ²
Cross section [AWG]	24 - 10 AWG
Strip length from	11 mm
Strip length to	12 mm
Material group	I



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
745-834	CCA	NL6296	400	41	0,02-6
745-834	cURus	E45172	300/150/300	30/30/10	24-10
745-834	KEMA	2076500.02	400	41	0,02-6
745-834	KEMA	2097989.01	400	41	0,02-6

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected