


Item no.: 745-851/006-000  
 Product description: MODULAR PCB TERMINAL BLOCK 4 SOLDER PINS/POLE 1  
 POLE PIN SPACING 10 MM / 0.394 IN

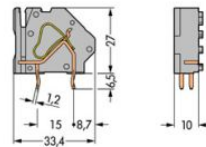

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	4 (Printed Circuit)
Weight	9 g
Color	gray
No. of connection Points	1
No. of potentials	1
pole count	1
Height	27 mm
Height	1.06 in
Width	10 mm
Width	0.394 in
Depth	33.4 mm
Depth	1.315 in
Pin spacing from	10 mm
Pin spacing from	0.394 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	76 A
Pollution degree	2

Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	76 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.2 - 16 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.2 - 16 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 10 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 10 mm <sup>2</sup>
Cross section [AWG]	24 - 6 AWG
Strip length from	12 mm
Strip length to	13 mm
Material group	I



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
745-851/006-000	CSA	154112-1604421	300	10	24-6
745-851/006-000	cURus	E45172	300	10	24-6

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected