


Item no.: 745-854/006-000  
 Product description: MODULAR PCB TERMINAL BLOCK 4 SOLDER PINS/POLE 1  
 POLE PIN SPACING 10 MM / 0.394 IN

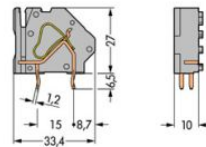

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

|                          |                     |
|--------------------------|---------------------|
| Product group            | 4 (Printed Circuit) |
| Weight                   | 9.001 g             |
| Color                    | blue                |
| No. of connection Points | 1                   |
| No. of potentials        | 1                   |
| pole count               | 1                   |
| Height                   | 27 mm               |
| Height                   | 1.06 in             |
| Width                    | 10 mm               |
| Width                    | 0.394 in            |
| Depth                    | 33.4 mm             |
| Depth                    | 1.315 in            |
| Pin spacing from         | 10 mm               |
| Pin spacing from         | 0.394 in            |
| Pollution degree         | 2                   |
| Measured voltage EN      | 320 V               |
| Measured shock voltage   | 4 kV                |
| Current intensity EN     | 76 A                |
| Pollution degree         | 2                   |

|                        |       |
|------------------------|-------|
| Measured voltage EN    | 630 V |
| Measured shock voltage | 4 kV  |
| Current intensity EN   | 76 A  |



|                                  |                           |
|----------------------------------|---------------------------|
| Connection method                | CAGE CLAMP® CONNECTION    |
| Cross section [mm <sup>2</sup> ] | 0.2 - 16 mm <sup>2</sup>  |
| Wiring method                    | solid                     |
| Cross section [mm <sup>2</sup> ] | 0.2 - 16 mm <sup>2</sup>  |
| Cross section [mm <sup>2</sup> ] | 0.25 - 10 mm <sup>2</sup> |
| Cross section [mm <sup>2</sup> ] | 0.25 - 10 mm <sup>2</sup> |
| Cross section [AWG]              | 24 - 6 AWG                |
| Strip length from                | 12 mm                     |
| Strip length to                  | 13 mm                     |
| Material group                   | I                         |



| Item no.        | Admission office | Approval no.   | Voltage [V] | Current [A] | Cross section [ mm <sup>2</sup> ] |
|-----------------|------------------|----------------|-------------|-------------|-----------------------------------|
| 745-854/006-000 | CSA              | 154112-1604421 | 300         | 10          | 24-6                              |
| 745-854/006-000 | cURus            | E45172         | 300         | 10          | 24-6                              |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected