


| : 756-9102/030-000

Fitted pluggable connector; 3-pole; M8 plug, straight; IDC technology



<https://www.wago.com/756-9102/030-000>

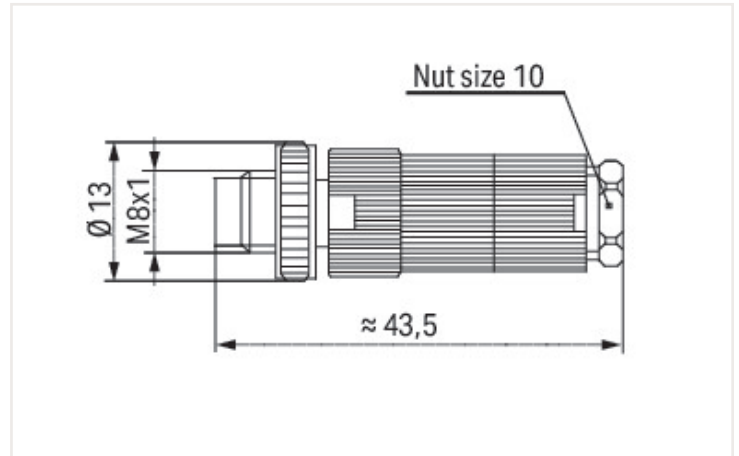

Dimensions in mm

#### Technical data

Connection type	M8 plug
Pole number	3
Cable connection direction to mating direction	0°

#### Connection data

Connection type 1	Pin penetration technology
Solid conductor	0.14 ... 0.34 mm <sup>2</sup>

#### Mechanical data

Connectable sheathed cable diameter	4 ... 5 mm
Weight	13.9 g

#### Environmental requirements

Protection type	IP67
Fire load	0.115 MJ

#### Commercial data

eCl@ss 10.0	27-24-26-92
eCl@ss 9.0	27-24-26-92
ETIM 8.0	EC002584
ETIM 7.0	EC002584
PU (SPU)	5 (1) Stück
Packaging type	Box
Country of origin VKOrg Germany	DE
GTIN	4044918977333
Customs tariff number VKOrg Germany	85366990990

## Downloads

### Environmental Product Compliance

#### Compliance Search

Environmental Product  
Compliance  
756-9102/030-000



## Documentation

### System Description

IP67 Cables and Plug-  
gable Connectors

pdf  
157.80 KB



### Bid Text

756-9102/030-000

19.02.2019

xml  
2.69 KB



756-9102/030-000

20.09.2017

doc  
23.50 KB



## CAD/CAE-Data

### CAE data

WSCAD Universe  
756-9102/030-000

