


| : 756-9105/030-000

Fitted pluggable connector; 3-pole; M8 plug, right angle; IDC technology



<https://www.wago.com/756-9105/030-000>

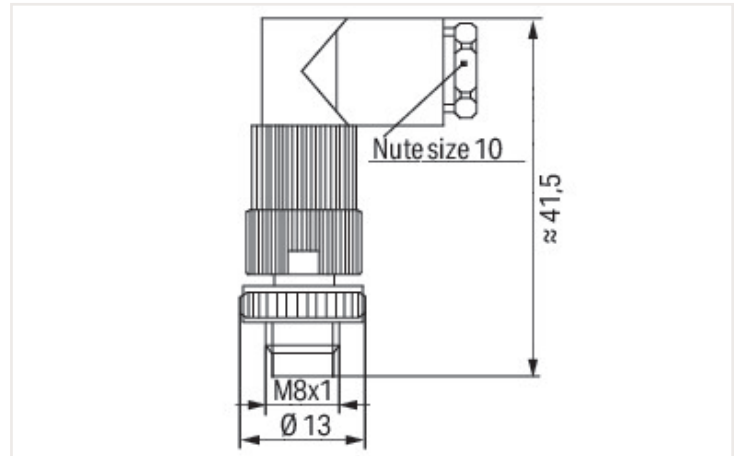

Dimensions in mm

Technical data

Connection type	M8 plug
Pole number	3
Cable connection direction to mating direction	90 °

Connection data

Connection type 1	Pin penetration technology
Solid conductor	0.14 ... 0.34 mm ²

Mechanical data

Connectable sheathed cable diameter	4 ... 5 mm
Weight	14.5 g

Environmental requirements

Protection type	IP67
Fire load	0.143 MJ

Commercial data

eCl@ss 10.0	27-24-26-92
eCl@ss 9.0	27-24-26-92
ETIM 8.0	EC002584
ETIM 7.0	EC002584
PU (SPU)	5 (1) Stück
Packaging type	Box
Country of origin VKOrg Germany	DE
GTIN	4044918977357
Customs tariff number VKOrg Germany	85366990990

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product
Compliance
756-9105/030-000



Documentation

System Description

IP67 Cables and Plug-
gable Connectors

pdf
157.80 KB



Bid Text

756-9105/030-000

19.02.2019

xml
2.69 KB



756-9105/030-000

20.09.2017

doc
23.50 KB



CAD/CAE-Data

CAE data

WSCAD Universe
756-9105/030-000

