
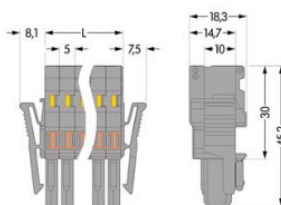


Item no.: 769-110/021-000
 Product description: 1-CONDUCTOR FEMALE PLUG WITH LATERAL LOCKING LEVERS ONLY TO BE USED FOR MALE CONNECTORS WITH CODING FINGERS COMMONING POSSIBILITY WITH MINIATURE ADJACENT JUMPERS 10 POLE

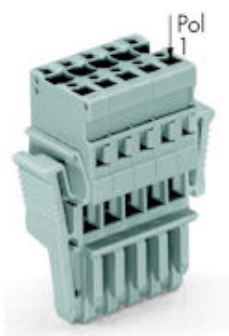

Produkt kann von Bild abweichen / product may differ

Packing unit 10 pieces

RoHS compliant

Product group	18 (X-COM-SYSTEM)
pole count	10
Cross section [mm ²]	0.08 - 4 mm ²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	32 A
Weight	35.869 g
Color	gray
Wiring type	Front-entry
No. of connection Points	10
No. of potentials	10
Height	45.2 mm
Height	1.78 in
Width	65.6 mm

Width	2.583 in
Depth	18.3 mm
Depth	0.72 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
769-110/021-000	ABS	05-HG476175/3-PDA	500	32	4
769-110/021-000	CSA	154112-1101144	300	20	28-12
769-110/021-000	KEMA	2077750.01	500	32	4
769-110/021-000	UR	E45171	600	20	16-12
769-110/021-000	UR	E45172	300	20	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected