


Item no.: 769-114/021-000
 Product description: 1-CONDUCTOR FEMALE PLUG WITH LATERAL LOCKING LEVERS 14 POLE ONLY TO BE USED FOR MALE CONNECTORS WITH CODING FINGERS COMMONING POSSIBILITY WITH MINIATURE ADJACENT JUMPERS

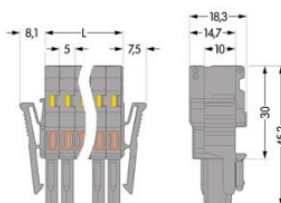

Packing unit 10 pieces

Product group	18 (X-COM-SYSTEM)
pole count	14
Cross section [mm ²]	0.08 - 4 mm ²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	32 A
Weight	53.666 g
Color	gray
Wiring type	Front-entry
No. of connection Points	14
No. of potentials	14
Height	45.2 mm
Height	1.78 in
Width	85.6 mm
Width	3.37 in
Depth	18.3 mm
Depth	0.72 in
Strip length from	8 mm
Strip length to	9 mm

Strip length

0.33 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
769-114/021-000	ABS	04-HG476175-PDA	500	32	4
769-114/021-000	CSA	154112-1101144	300/300/600	20/20/5	28-12
769-114/021-000	KEMA	2077750.01	500	32	4
769-114/021-000	UR	E45171	600	20	16-12
769-114/021-000	UR	E45172	300/300/600	20/20/5	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected