


Item no.: 769-612/002-000  
 Product description: Plug WITH CAGE CLAMP®CONNECTION AND FIXING FLANGES FOR SCREW OR SIMILAR MOUNTING TYPES FOR PARALLEL OR PERPENDICULAR MOUNTING PIN SPACING 5 MM / 0.197 IN 12 POLE

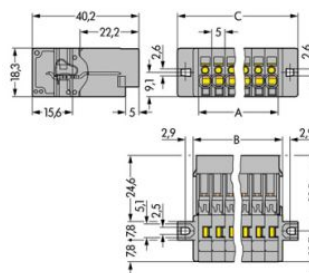

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	18 (X-COM-SYSTEM)
Pin spacing from	5 mm
Pin spacing from	0.197 in
pole count	12
Cross section [mm <sup>2</sup> ]	0.08 - 4 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	32 A
Weight	36.468 g
Color	gray
Wiring type	Front-entry
No. of connection Points	12
No. of potentials	12
Height	18.3 mm
Height	0.72 in

Width	75.4 mm
Width	2.969 in
Depth	40.2 mm
Depth	1.583 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
769-612/002-000	ABS	05-HG476175/3-PDA	500	32	4
769-612/002-000	CSA	154112-1101144	300	20	28-12
769-612/002-000	KEMA	2077750.01	500	32	4
769-612/002-000	UR	E45171	600	20	16-12
769-612/002-000	UR	E45172	300	20	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected