


Item no.: 769-672/003-000

Product description: HEADERS WITH FIXING FLANGE 12 POLE RIGHT ANGLE SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN PIN SPACING 5 MM / 0.197 IN MATING DIRECTION PARALLEL TO PCB

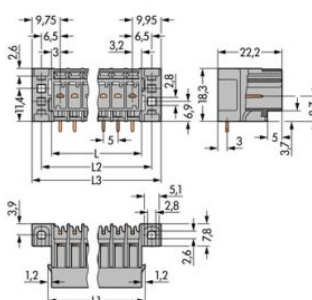

Packing unit 25 pieces

Product group	18 (X-COM-SYSTEM)
Pin spacing from	5 mm
Pin spacing from	0.197 in
pole count	12
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	32 A
Measured voltage EN	500 V
Measured shock voltage	4 kV
Pollution degree	2
Weight	13.49 g
Color	gray
Wiring type	Front-entry
No. of connection Points	12
No. of potentials	12
Height	18.3 mm
Height	0.72 in
Width	74.7 mm
Width	2.941 in
Depth	22.2 mm
Depth	0.874 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
769-672/003-000	ABS	04-HG476175-PDA	500	32	4
769-672/003-000	CSA	154112-1101144	300/300/600	20/20/5	28-12
769-672/003-000	KEMA	2077750.01	500	32	4
769-672/003-000	UR	E45171	600	20	16-12
769-672/003-000	UR	E45172	300	20	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected