


Item no.: 769-675/003-000
 Product description: HEADERS WITH FIXING FLANGE 15 POLE RIGHT ANGLE
 SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN PIN SPACING 5
 MM / 0.197 IN MATING DIRECTION PARALLEL TO PCB

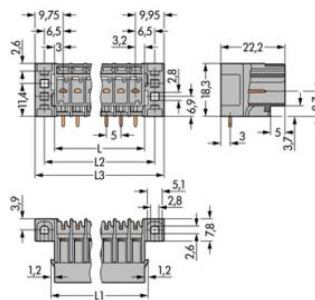

Packing unit 15 pieces

Measured voltage EN	500 V
Pollution degree	2
Strip length from	mm
Measured shock voltage	4 kV
Product group	18 (X-COM-SYSTEM)
Pin spacing from	5 mm
Pin spacing from	0.197 in
pole count	15
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	32 A
Weight	16.74 g
Color	gray
Wiring type	Front-entry
No. of connection Points	15
No. of potentials	15
Height	18.3 mm
Height	0.72 in
Width	89.7 mm
Width	3.531 in
Depth	22.2 mm
Depth	0.874 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
769-675/003-000	ABS	04-HG476175-PDA	500	32	4
769-675/003-000	CSA	154112-1101144	300/300/600	20/20/5	28-12
769-675/003-000	KEMA	2077750.01	500	32	4
769-675/003-000	UR	E45171	600	20	16-12
769-675/003-000	UR	E45172	300/300/600	20/20/5	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected