


Item no.: 773-112  
 Product description: PUSH-WIRE CONNECTOR FOR JUNCTION BOXES 2-CONDUCTOR TERMINAL BLOCKS

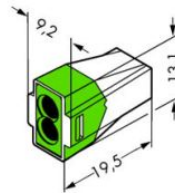

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Product group	7 (Push Wire Conn.)
pole count	2
Cross section [mm <sup>2</sup> ]	1.5 - 2.5 mm <sup>2</sup>
Cross section [AWG]	14 - 12 AWG
Connection method	PUSH WIRE®
Number of strands	2
Cross section [mm <sup>2</sup> ]	1 - 2.5 mm <sup>2</sup>
Cross section [AWG]	14 - 12 AWG
Wiring method	e
Number of strands	2
Measured voltage EN	400 V
Measured shock voltage	4 kV
Pollution degree	2
Current intensity EN	24 A
Weight	1.847 g
Color	green
No. of connection Points	2
No. of potentials	1
Height	13.1 mm
Height	0.516 in

Width  
Width

9 mm  
0.354 in



Depth	19.1 mm
Depth	0.752 in
Strip length from	10 mm
Strip length to	13 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
773-112	ABS	04-HG476172/1-PDA	400	24	0,75-2,5
773-112	BV	11941/BO	300	24	2,5
773-112	CB-certificateChina	DK2689/A1	400	24	0,75-2,5
773-112	CCA	DK2520	400	24	0,75-2,5
773-112	CSA	154112-1059435	600	20	12-18
773-112	DEMKO	99-03689	400	24	0,75-2,5
773-112	FIMKO	FI14401	400	24	0,75-2,5
773-112	GL	17294-00HH	400	24	0,75-2,5
773-112	LR	04/20013(E3)	400	24	0,75-2,5
773-112	NEMKO	P99102807	400	24	0,75-2,5
773-112	RMR	11130002	400	24	0,75-2,5
773-112	SEMKO	9951003/01	400	24	0,75-2,5
773-112	UL	E201573			12-18

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected