


Item no.: 773-116  
 Product description: PUSH-WIRE CONNECTOR FOR JUNCTION BOXES 6-CONDUCTOR TERMINAL BLOCK

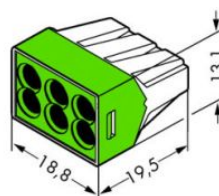

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

Product group	7 (Push Wire Conn.)
pole count	6
Cross section [mm <sup>2</sup> ]	1.5 - 2.5 mm <sup>2</sup>
Cross section [AWG]	14 - 12 AWG
Connection method	PUSH WIRE®
Number of strands	6
Cross section [mm <sup>2</sup> ]	1 - 2.5 mm <sup>2</sup>
Cross section [AWG]	14 - 12 AWG
Wiring method	e
Number of strands	6
Measured voltage EN	400 V
Measured shock voltage	4 kV
Pollution degree	2
Current intensity EN	24 A
Weight	4.25 g
Color	green
No. of connection Points	6
No. of potentials	1
Height	13.1 mm
Height	0.516 in

Width  
Width

19 mm  
0.748 in



Depth	19.1 mm
Depth	0.752 in
Strip length from	10 mm
Strip length to	13 mm
Strip length	0.45 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
773-116	ABS	04-HG476172/1-PDA	400	24	0,75-2,5
773-116	BV	11941/BO	300	24	2,5
773-116	CB-certificateChina	DK2689/A1	400	24	0,75-2,5
773-116	CCA	DK2520	400	24	0,75-2,5
773-116	CSA	154112-1059435	600	20	12-18
773-116	DEMKO	99-03689	400	24	0,75-2,5
773-116	FIMKO	FI14401	400	24	0,75-2,5
773-116	GL	17294-00HH	400	24	0,75-2,5
773-116	LR	04/20013(E3)	400	24	0,75-2,5
773-116	NEMKO	P99102807	400	24	0,75-2,5
773-116	RMR	11130002	400	24	0,75-2,5
773-116	SEMKO	9951003/01	400	24	0,75-2,5
773-116	UL	E201573			12-18

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected