


Item no.: 805-103
 Product description: PCB TERMINAL STRIP 1 SOLDER PIN / POLE STAGGERED
 3 POLE PIN SPACING 3.5 MM / 0.138 IN WITH PUSH
 BOTTOMS WITH TEST SLOT FOR Ø

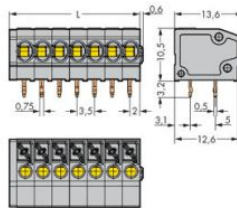

Packing unit 1 piece

Weight	1.482 g
Color	gray
No. of connection Points	3
No. of potentials	3
pole count	3
Height	10.5 mm
Height	0.413 in
Width	12 mm
Width	0.472 in
Depth	13.6 mm
Depth	0.535 in
Pin spacing from	3.5 mm
Pin spacing from	0.137 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	17.5 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	17.5 A
Connection method	CAGE CLAMP® CONNECTION



Cross section [mm ²]	0.2 - 1.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.2 - 1.5 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [mm ²]	0.25 - 1 mm ²
Cross section [AWG]	24 - 16 AWG
Strip length from	9 mm
Strip length to	10 mm
Material group	I
xxx-xxx/000-006	blue
xxx-xxx/000-012	orange

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected