


Item no.: 831-3104  
 Product description: FEMALE CONNECTOR 4 POLE PIN SPACING 7.62 MM / 0.3 IN 100% PROTECTED AGAINST MISMATING WITH CODING FINGERS

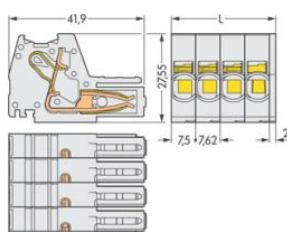

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Weight	30.186 g
Color	light gray
No. of connection Points	4
No. of potentials	4
pole count	4
Height	27.55 mm
Height	1.085 in
Width	32.36 mm
Width	1.274 in
Depth	41.9 mm
Depth	1.65 in
Pin spacing from	7.62 mm
Pin spacing from	0.3 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	41 A
Pollution degree	2

Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	41 A
Connection method	CAGE CLAMP®S Connection



Cross section [mm <sup>2</sup> ]	0.5 - 10 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.5 - 10 mm <sup>2</sup>
Wiring method	fine-stranded
Cross section [mm <sup>2</sup> ]	0.5 - 6 mm <sup>2</sup>
Wiring method	fine-stranded (with ferrule and plastic collar)
Cross section [mm <sup>2</sup> ]	0.5 - 6 mm <sup>2</sup>
Wiring method	fine-stranded (with ferrule, without plastic collar)
Cross section [AWG]	20 - 8 AWG
Additional clamping spring	Nickel-chromium spring steel (CrNi)
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
831-3104	CSA	154112-1466354	600	50	20-8
831-3104	PSE	JET0695-43009-1003	300/600	42/5	20-8
831-3104	UR	E45172	600	42	20-8

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected