
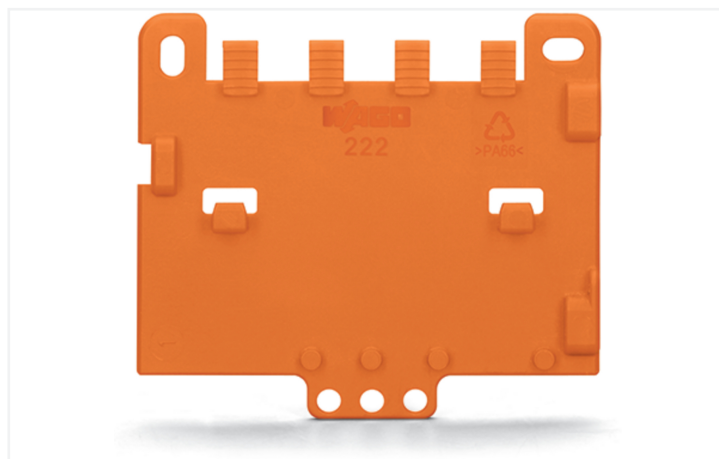


Data Sheet | Item Number: 222-505

Strain relief plate; for mounting carrier; 221 or 222 Series, can be snapped

<https://www.wago.com/222-505>

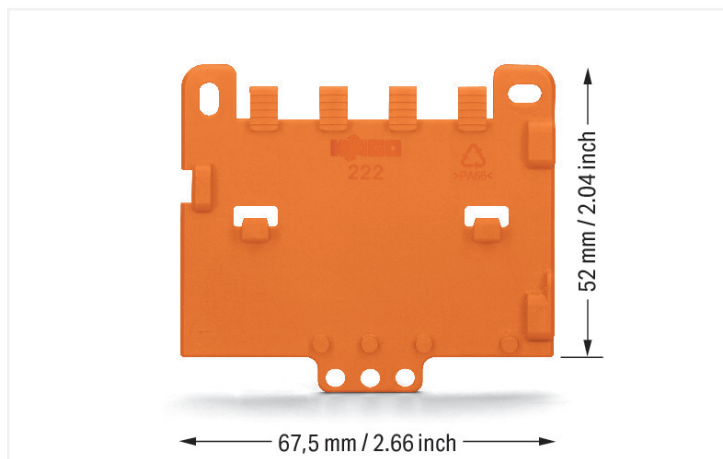

Physical data

Width	4 mm / 0.157 inches
Height	67 mm / 2.638 inches
Depth from upper-edge of DIN-rail	52 mm / 2.047 inches
Depth	58 mm / 2.283 inches

Mechanical data

Suitable	for mounting carriers (221 and 222 Series)
----------	--

Material data

Note (material data)	Information on material specifications can be found here
Fire load	0.168 MJ
Weight	5.6 g

Commercial data

Product Group	7 (Push Wire Conn.)
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 8.0	EC002848
PU (SPU)	50 (10) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454714789
Customs tariff number	85389099990

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 222-505	↓

Documentation

Bid Text			
222-505	19.02.2019	xml 2.69 KB	↓
222-505	19.05.2017	doc 23.50 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 222-505	↓

CAE data	
EPLAN Data Portal 222-505	↓
WSCAD Universe 222-505	↓
ZUKEN Portal 222-505	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Mounting adapter


1.1.1.1 Mounting accessories




Item No.: 221-500
 Mounting carrier; 221 Series - 4 mm²; for DIN-35 rail mounting/screw mounting; orange

Item No.: 222-500
 Mounting carrier; 222 Series; for DIN-35 rail mounting/screw mounting; orange

Installation Notes

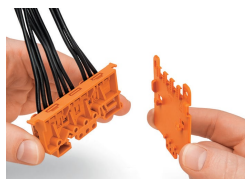

Securing a strain relief plate (222-505) to the mounting carrier.

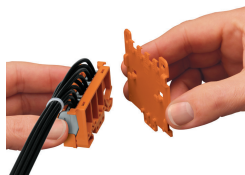

Securing a strain relief plate (222-505) to the mounting carrier.