

Color:  natural**Technical data**

Number of spacings	1 -times
--------------------	----------

**Physical data**

Depth	50 mm / 1.97 inches
Pin spacing	5/7.62 mm

**Mechanical data**

Suitable	for male and female connectors with CAGE CLAMP® connection
----------	--

**Material data**

Color	natural
Material group	I
Insulation material (main housing)	Glass fiber-reinforced polyamide (PA66 GF)
Flammability class per UL94	HB
Fire load	0.038 MJ
Weight	1.4 g

**Commercial data**

Product Group	3 (Multi Conn. System)
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 8.0	EC002848
ETIM 7.0	EC002848
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332117661
Customs tariff number	39269097900

## Environmental Product Compliance

RoHS Compliance Status

Compliant, No Exemption

## Approvals / Certificates

## General approvals



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2	1466354

## Approvals for marine applications



Approval	Standard	Certificate Name
LR Lloyds Register	IEC 61984	96/20035 (E5)

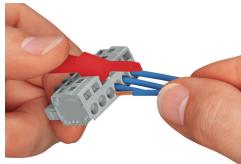
## Downloads

## Environmental Product Compliance

## Compliance Search

Environmental Product  
Compliance 231-159

## Installation Notes

Conductor termination parallel to CAGE  
CLAMP® actuationConductor termination perpendicular to  
CAGE CLAMP® actuation