



Color: ■ red

#### Technical data

Number of spacings	1 -times
--------------------	----------

#### Physical data

Depth	50 mm / 1.97 inches
Pin spacing	5/7.62 mm

#### Mechanical data

Suitable	for male and female connectors with CAGE CLAMP® connection
----------	--

#### Material data

Color	red
Insulation material (main housing)	Glass fiber-reinforced polyamide (PA66 GF)
Fire load	0.038 MJ
Weight	1.3 g

#### Commercial data

Product Group	3 (Multi Conn. System)
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 8.0	EC002848
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454830106
Customs tariff number	82055980000

## Environmental Product Compliance

RoHS Compliance Status

Compliant, No Exemption

## Approvals / Certificates

## General approvals



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2	1466354

## Approvals for marine applications



Approval	Standard	Certificate Name
LR Lloyds Register	IEC 61984	96/20035 (E5)

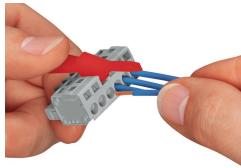
## Downloads

## Environmental Product Compliance

## Compliance Search

Environmental Product  
Compliance 231-231

## Installation Notes

Conductor termination parallel to CAGE  
CLAMP® actuationConductor termination perpendicular to  
CAGE CLAMP® actuation