

Datasheet

Item No. 70.320.2428.0

Bottom BAS GUT GA 24 50 A

revos BASIC 500V size 24 open-bottom base, double locking lever



Item No.	70.320.2428.0
EAN	4015573220119
order unit	1 Piece(s)

Approvals



Technical data


General

Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Equipment mounted (feed-through)
Locking mechanism	Double locking levers
Cable entry	None
Type of cable	None
With cable screw gland	No
Hinged lid	No
EMC-version	No

Drawings

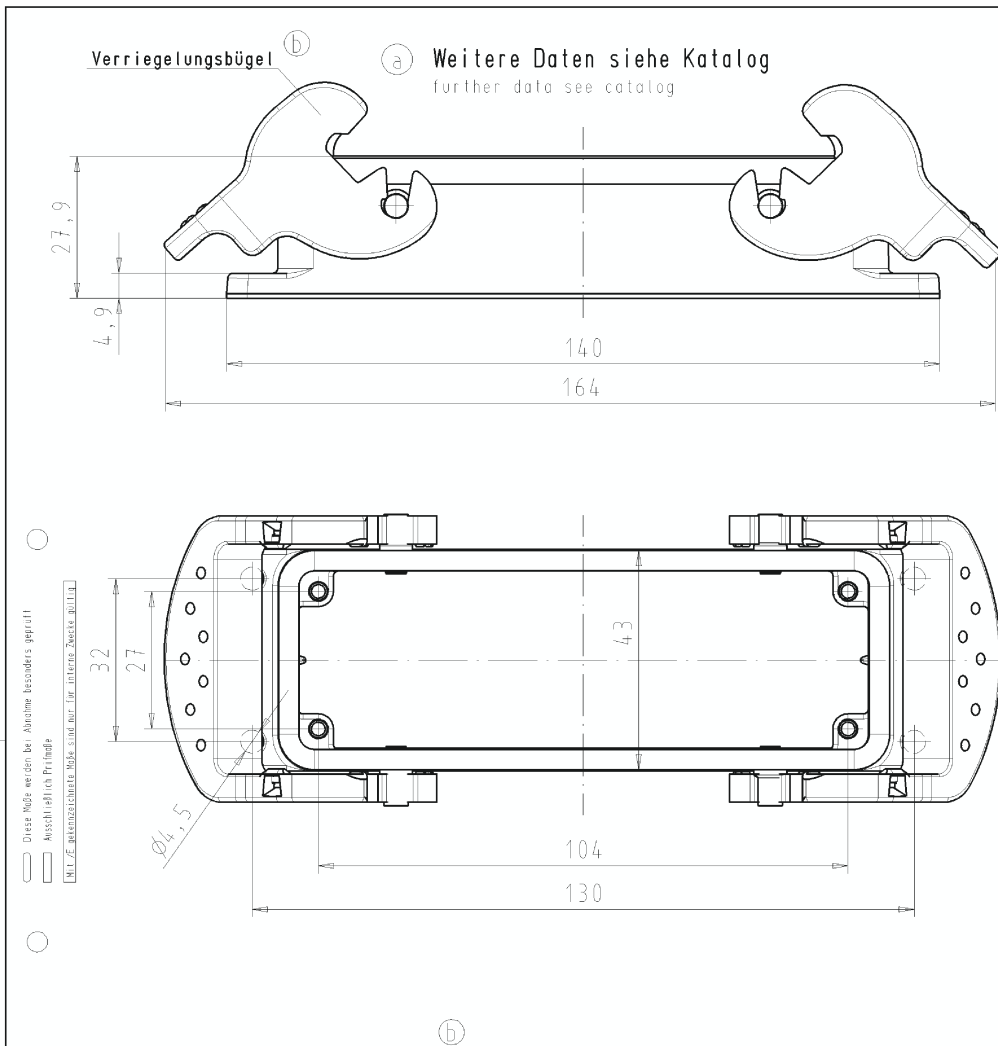

70.320.2410.0	Stahl / steel	BAS GUT GA 24 5S A
70.320.2419.0	Edelstahl / stainless steel	BAS GUT GA 24 5V A
70.320.2428.0	Kunststoff / synthetic material	BAS GUT GA 24 50 A
Teile-Nummer part-number	Verriegelungsbügel locking levers	TYP / type
Frei-toleranz nach -		
CAD - Zeichnung, keine manuellen Änderungen		
1. Verwendung: -		
Bl.: 1 von 1		
Maßstab		
Werkstoff und Oberfläche:		
2003 Tag Name		
Entworfen 10.07. Bauer F.		
Geprüft - -		
Normgepr. - -		
Ersatz für: -		
Vol. mm² Dtl. mm²		
b 16.07.2004/		
a 23.04.2004/		
Buchstabe Datum / Blatt		
Änderung		
Typ		
BAS GUT GA		
24 50 A		
Benennung		
GEHAEUSE_UNTERTEIL		
Größe 24 offen		
OPEN HOUSING size 24		

7030242801K_4 CADW100 Posler 2004-07-16 13:25:59 1:000