


Datasheet

Item No. 56.703.9155.0

Duo-ground block WKFN 2,5D2/2/SL/35

Duo earth terminal block with spring clamp connection for mounting on TS 35, nominal cross section 2.5 mm², width 5 mm, color green/yellow

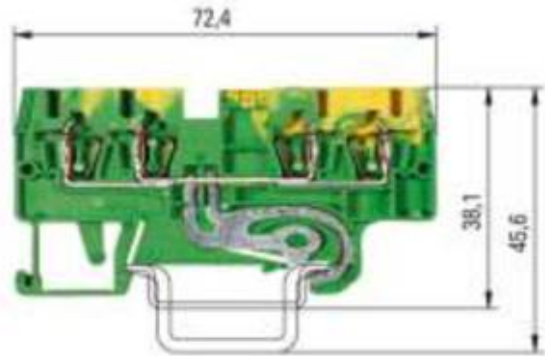

Item No.	56.703.9155.0
EAN	4015573718388
order unit	100 Piece(s)

Approvals



Technical data

General

Nominal cross section	2.5 mm ²
Colour	Green/yellow
Number of levels	1
Number of clamp positions per level	4
Width/grid dimension	5 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	Yes

Technical data

Rated impulse voltage	8
Pollution degree	3
Closing plate required	Yes
Length	72.4 mm
Type of insulation material	Thermoplastic

Connection Data

Connection type 1	Tension clamp connection
Connection type 2	Tension clamp connection
Minimum cross section solid	0.13 mm ²
Maximum cross section solid	4 mm ²
Minimum cross section fine stranded	0.13 mm ²

Maximum cross section fine stranded	2.5 mm ²
Wire strip length	11 mm

Technical Data UL/CSA

Cross section UL	22-12 AWG
Cross section CSA	24-12 AWG

Accessories

Item. No.	Typ:	Description:
04.343.8353.8	Warning cover ADF.../4 YELLOW	Cover with warning symbol for DIN rail terminal blocks type WKF ...
98.300.0000.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, unslotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.300.1000.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, slotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.300.1900.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, slotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.360.0000.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.360.0004.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel, hot galvanized
98.370.0000.0	Mounting rail 35x27x15(EN60715)2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.370.1000.0	Mounting rail 35x27x15(EN60715)2000MM	Mounting rail TS 35, slotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.380.0000.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material E copper

Drawings

Hutschiene EN 60715-35x7,5
mounting rail EN 60715-35x7,5

Hutschiene EN 60715-35x15
mounting rail EN 60715-35x15

M1:1

Weitere Daten siehe Katalog
further data see catalog

Freileitungs nach -		CAD - Zeichnung, keine manuellen Änderungen			1. Vorwandung: -		Bl: 1 von 1	
/	M3Bstab	-	2003	Tag	Name	Zeichnung Nr.		Index
/	2:1		Entworfen	26.05.	Schnitt 1.	56.703.9155.0 01K		
/			Geprüft	-	-			
/			Normpage.	-	-	Ersatz für: -		
Bemerkung		wieland		Bemerkung		DUO_SCHUTZLEITERKLEMME		
Änderung		Wahlweise Verbindungen		NKFEN 2,5 D1/Z/SL/35		400-PE terminal		

56703915001K_4 CADW100 Schnitt: 26.05.2003 1011849 1.000