


Data sheet

Commercial Art.No.: 21.305.0257.0

Europe terminal strip 4E / 2DS GW

Europa terminal strips with wire protection, 2-pole, nominal cross section: 1.5mm², width: 8mm, rated voltage: 400V, color: white

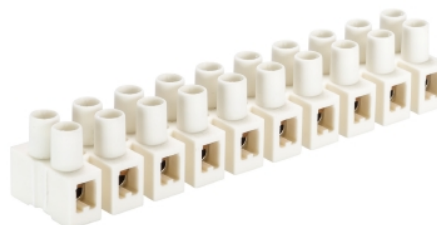

Commercial Art.No.	21.305.0257.0
EAN	4015573894495
Order Unit	2000

Certificates / Approvals



Technical data

Classification

ECLASS 11	
ECLASS 8.1	27141106
ETIM 7.0	EC001284
ETIM 6.0	
ETIM 5.0	EC001284
ETIM 4.0	EC001284
ETIM 3.0	EC001284

Technical data

Drill hole distance centrally	8 mm
Rated voltage	400 V
Type of electrical connection 1	Screw connection
Model electrical connection 2	Screw connection
Number of poles	2
Number of clamp positions per pole	2
Mounting method	Direct mounting
Operating temperature	-40-100°C
Inflammability class of insulation material acc. with UL94	V2
Width	14 mm
Rastermaß	8 mm
Height NS 35/7,5	15 mm
Length	16 mm
End plate necessary	No
Color	Grey
Transparent	No

Product compliance

ROHS conformity status	Compliant/Exempted
ROHS exceptions	III-6(c)

REACH-SVHC conformity status	Duty-To-Declare
REACH-SVHC substances	Lead
REACH-SVHC CAS numbers	7439-92-1