


Two-tier insulated headers for PC boards

Spacings: 5.00/5.08 mm


wiecon

Rated current:
10 A

250 V/4 kV/3 – Overvoltage category III
400 V/4 kV/2 – Overvoltage category II
1000 V/4 kV/1 – Overvoltage category I

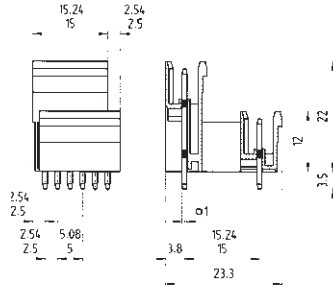

Solder pin 1 x 1 mm
Bore hole Ø 1.4 mm

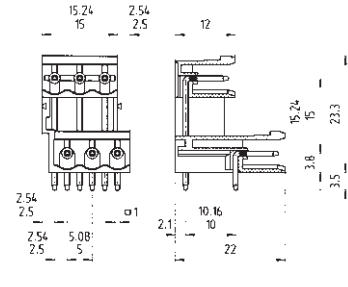

Solder pin 1 x 1 mm
Bore hole Ø 1.4 mm

Type 8113 SE/... G, 8213 SE/... G

vertical mount

Type 8113 SE/... W, 8213 SE/... W

horizontal mount

Rated voltages: VDE 0110
UL ratings
CSA ratings
Approvals

300 V 15 A
300 V 10 A

300 V 15 A
300 V 10 A



Std. pack	T	Poles	Part no.	Part no.	Part no.
Spacing: 5.00 mm			unmarked		unmarked
100	5	2 x 2	25.334.3253.0		25.336.3253.0
100	10	2 x 3	25.334.3353.0		25.336.3353.0
Slide together for larger pole configurations. Factory assembly available.					
Spacing: 5.08 mm			unmarked		unmarked
100	5.08	2 x 2	25.354.3253.0		25.356.3253.0
100	10.16	2 x 3	25.354.3353.0		25.356.3353.0
Slide together for larger pole configurations. Factory assembly available.					
Accessories:					
End plate	50		07.310.9853.0		07.310.9853.0
Fixing device assembly - for screw flanges on both sides of the header			upon request		only together with end plate 07.310.9853.0 Z5.523.2453.0