


Data sheet

Commercial Art.No.: 56.703.9155.0

Duo-ground block WKFN 2,5 D2/2/SL/35

Duo Ground terminal with tension spring connection for mounting on TS 35, nominal cross section: 2.5 mm², width: 5 mm, color: Green-yellow

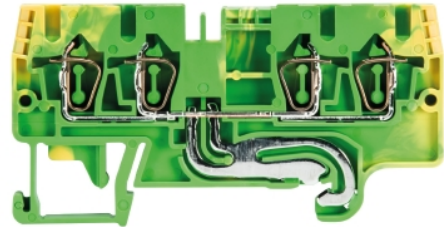

Certificates / Approvals



CAN-Ex



PTB



USA-Ex



Technical data

General

Nominal cross section	2.5 mm ²
Color	Green/yellow
Number of levels	1
Number of clamp positions per level	4
Width/grid dimension	5 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Explosion-tested version "Ex e"	Yes
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	Yes

Technical data

Rated voltage	800 V
Rated impulse voltage	8 kV
Pollution degree	3
Closing plate required	Yes
Type of insulation material	Thermoplastic
Length	72.4 mm

Connection Data

Connection type 1	Spring clamp connection
Connection type 2	Spring clamp connection
Minimum cross section solid	0.13 mm ²
Maximum cross section solid	4 mm ²
Minimum cross section fine stranded	0.13 mm ²
Maximum cross section fine stranded	2.5 mm ²
Wire strip length	11 mm

Technical Data UL/CSA

Cross section UL	22-12 AWG
Voltage UL	600 V


Cross section CSA	24-12 AWG
Voltage CSA	600 V

Classification

ECLASS 11	
ECLASS 8.1	27141141
ETIM 7.0	EC000901
ETIM 6.0	EC000901
ETIM 5.0	EC000901
ETIM 4.0	EC000901
ETIM 3.0	EC000901



Product compliance

ROHS conformity status	Compliant
REACH-SVHC conformity status	Compliant

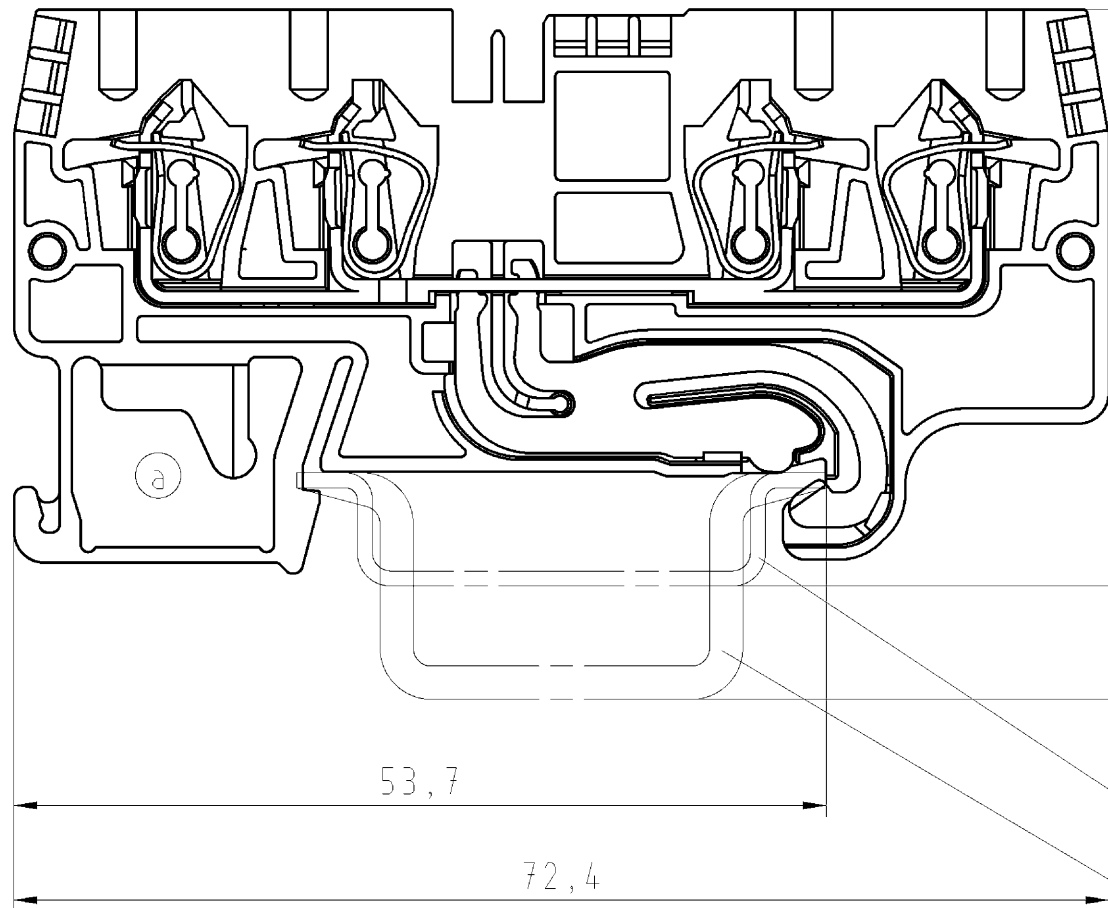

Hutschiene EN 60715-35x7,5
mounting rail EN 60715-35x7,5

 Hutschiene EN 60715-35x15
mounting rail EN 60715-35x15

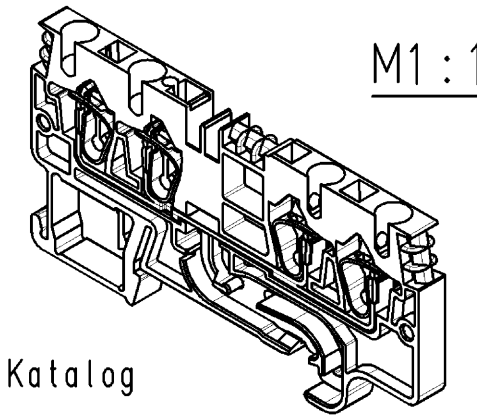

Weitere Daten siehe Katalog
further data see catalog

Freitoleranz nach -		CAD - Zeichnung, keine manuellen Änderungen			1. Verwendung: -		Bl.: 1 von 1	
	/	Maßstab	-	2003	Tag	Name	Zeichnung Nr.	
	/	2:1		Entworfen	26.05.	Schmitt J.	56.703.9155.0 01K a	
	/			Geprüft	-	-	Index	
	/	Vol.	mm ³	Glt.	mm ²	Normgepr.	Ersatz für: -	
	/	a		05.04.2012/	Benennung		DUO_SCHUTZLEITERKLEMME	
Buchstabe	Datum / Blatt	wieland Elektrische Verbindungen		WKN 2,5 D2/2/SL/35		duo-PE terminal		
Änderung								

○ Diese Maße werden bei Abnahme besonders geprüft
□ Ausschließlich Prüfmaße

Mit PE gekennzeichnete Maße sind nur für interne Zwecke gültig

Weitergabe sowie Vervielfältigung dieses Dokuments, Verwertung und Mitteilung seines Inhalts sind verboten, soweit nicht ausdrücklich gestattet. The reproduction, distribution and utilization of this document as well as the communication of its contents to others without express authorization is prohibited.