

Data sheet

Commercial Art.No.: 70.320.2428.0

Bottom BAS GUT GA 24 A

Bottom-base revos basic made of aluminum, with double locking lever or screw cap, low version, 24-poles



Certificates / Approvals



Technical data

General

Housing material	aluminum
Color	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

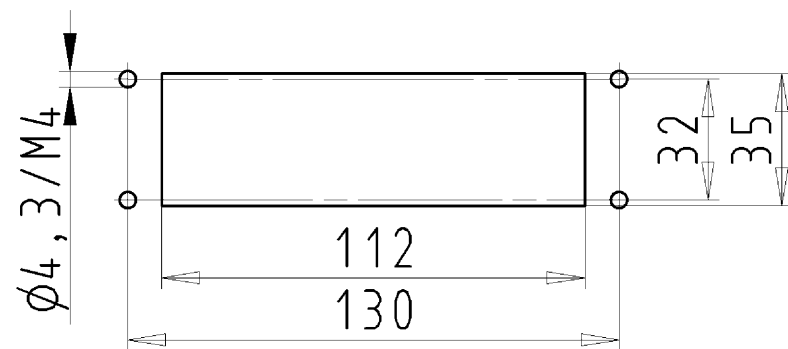
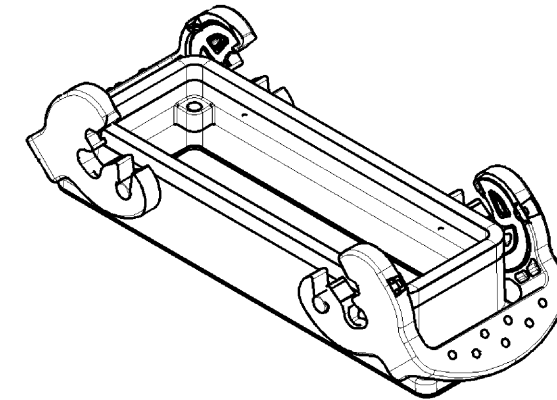
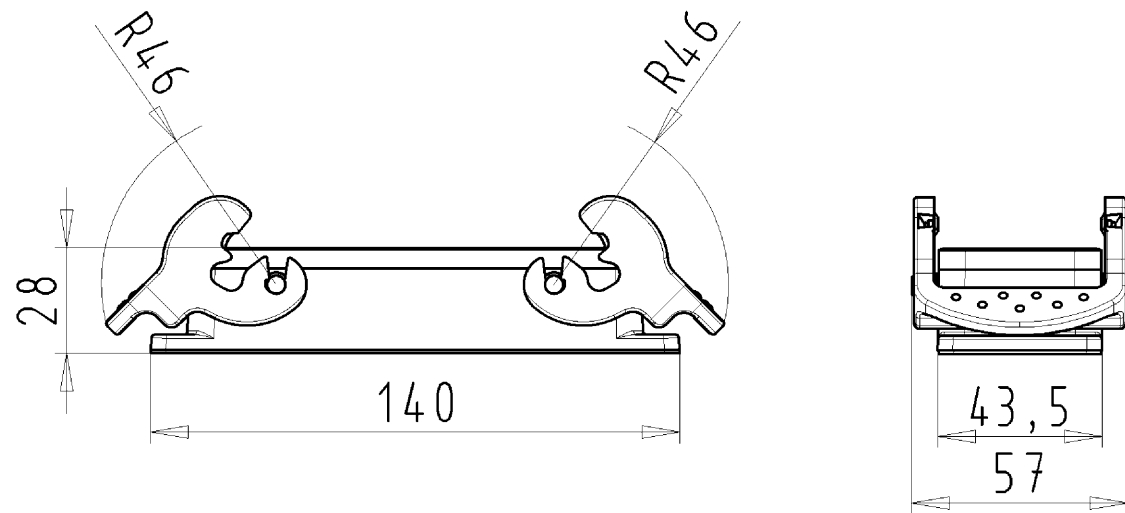
Model

Construction	24
Model	Equipment mounted (feed-through)
Locking mechanism	Double locking levers
Cable entry	None
Type of cable	None
With cable screw gland	No
Thread size PG	
Hinged lid	No
EMC-version	No
Length	140 mm
Width	57 mm
Height	28 mm

Classification

ECLASS 11	
ECLASS 8.1	27440202
ETIM 7.0	EC000437
ETIM 6.0	EC000437
ETIM 5.0	EC000437
ETIM 4.0	EC000437

REACH-SVHC conformity status	Compliant
------------------------------	-----------

Bohrbild
/Cut out

70.320.2428.0	BAS GOT GA 24 A	
Bestellnummer /Order number	Typ /Type	
Weitere Daten siehe KATALOG oder eKatalog. Additional data see CATALOG or eCatalog.		www.wieland-electric.com www.eshop.wieland-electric.com

Tolerierung Size ISO 14405 (C) / Tolerance system Size ISO 14405 (C). (This ISO-standard describes the envelope principle. According to the envelope principle the deviations of form and parallelism are limited by the size tolerances).						ja/yes ☒ Stoffverbats- und Deklarationsliste nach UU-TQM-05/03 ist einzuhalten. Conformity with Wieland document UU-TQM-05/03 (list of prohibited / delectable hazardous substances) to be declared!							
Freitoleranz nach General tolerance - - - - -				CAD - Zeichnung, keine manuellen Änderungen CAD - drawing, no manual modifications allowed				1. Verwendung: First Use: - - - -				Blatt: 1 von 1 Sheet: 1 of 1	
	/		Werkstoff/Material Aluminium beschichtet/coated grau/grey	2013	Tag/Date	Name	Zeichnung Nr./Drawing No. 70.320.2428.0 13K	Index					
	/			gezeichnet drawn	17.06.	Duetsch T.							
	/			Maßstab/Scale 1:2	geprüft checked	-			-				
	/			Normgepr. Stand. check	-	-			Maße in mm/Dimensions are in mm				
	/	Vol. mm³ Offl./Surf. mm²		Ersatz für/Replacement for: -									
	/		wieland Elektrische Verbindungen	Type revos BASIC	Benennung/Title GEHAEUSEUNTERTEIL Baugröße 24 offen OPEN HOUSING size 24								
	/												
Index	Datum / Blatt Date / Sheet												
Änderung/Revision													