 


Data sheet

Commercial Art.No.: 70.320.3228.0

Bottom BAS GUT GA 32 50 A

Bottom-base revos basic made of aluminum, with double locking lever or screw cap, low version, 32-poles



Certificates / Approvals



Technical data

General

Housing material	aluminum
Color	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model


Construction	32
Model	Equipment mounted (feed-through)
Locking mechanism	Double locking levers
Cable entry	None
Type of cable	None
With cable screw gland	No
Thread size PG	
Hinged lid	No
EMC-version	No
Length	124 mm
Width	84 mm
Height	35 mm

Classification

ECLASS 11	
ECLASS 8.1	27440202
ETIM 7.0	EC000437
ETIM 6.0	EC000437
ETIM 5.0	EC000437
ETIM 4.0	EC000437

Product compliance

REACH-SVHC conformity status	Compliant
------------------------------	-----------

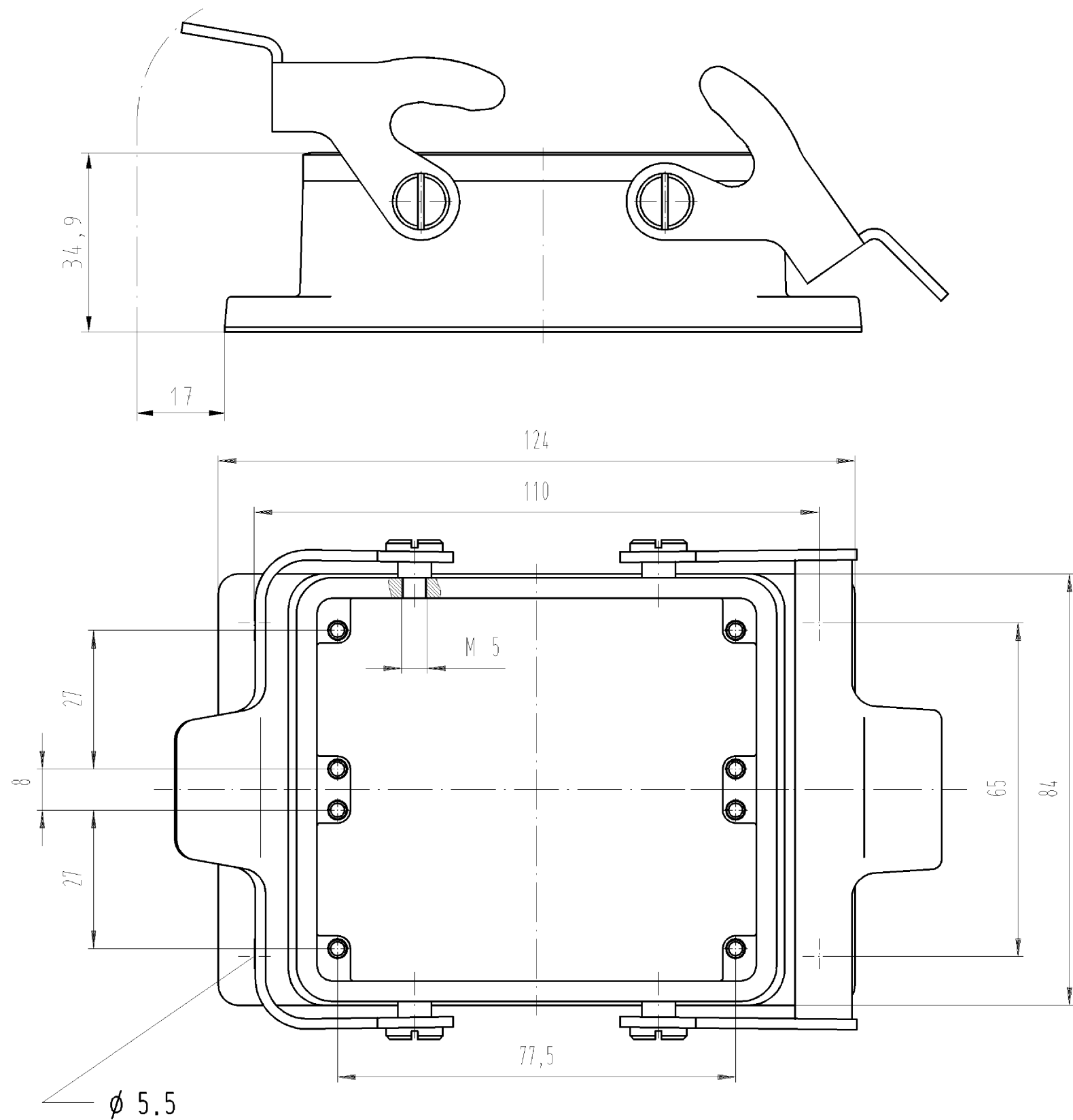

Freitoleranz nach				CAD - Zeichnung, keine manuellen Änderungen				1.Verwendung: -				Bl.: 1 von 1	
	/	Maßstab 1:1	Werkstoff und Oberfläche:		2003	Tag	Name		Zeichnung Nr.				Index
	/				Entworfen	10.07.	Bauer F.		70.320.3228.0 01K				
	/				Geprüft	-	-						
	/	Vol.	mm³	Off.	mm²	Normgepr.	-	-	Ersatz für: -				
	/		wieland		Typ BAS GUT GA 32 50 A		Benennung GEHAEUSE_UNTERTEIL Größe 32 offen OPEN HOUSING size 32						
	/												
Buchstabe	Datum / Blatt												
Änderung				Elektrische Verbindungen									

Weitergabe sowie Vervielfältigung dieses Dokuments, Verwertung und Mitteilung seines Inhalts sind verboten, soweit nicht ausdrücklich gestattet.
The reproduction, distribution and utilization of this document as well as the communication of its contents to others without express authorization is prohibited.