

Data sheet

Commercial Art.No.: 73.353.6435.1

Hood BAS GOT GA 24H M32 A1

Hood revos basic made of aluminum, for double locking lever or. screw cap with threaded hole M32 on the right side, low version, 24-poles



Technical data

General

Housing material	aluminum
Color	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

Construction	24H
Model	male
Locking mechanism	Double locking levers
Cable entry	Sideways
Type of cable	Thread
With cable screw gland	No
Thread size M	32
Thread size PG	
Hinged lid	No
EMC-version	No
Length	120 mm
Width	57 mm
Height	76 mm

Classification


ECLASS 11	
ECLASS 8.1	27440202
ETIM 7.0	EC000437

ETIM 6.0	EC000437
ETIM 5.0	EC000437
ETIM 4.0	EC000437
ETIM 3.0	EC000437

Product compliance

REACH-SVHC conformity status	Compliant
------------------------------	-----------

6 QU-MEE-01/14 a

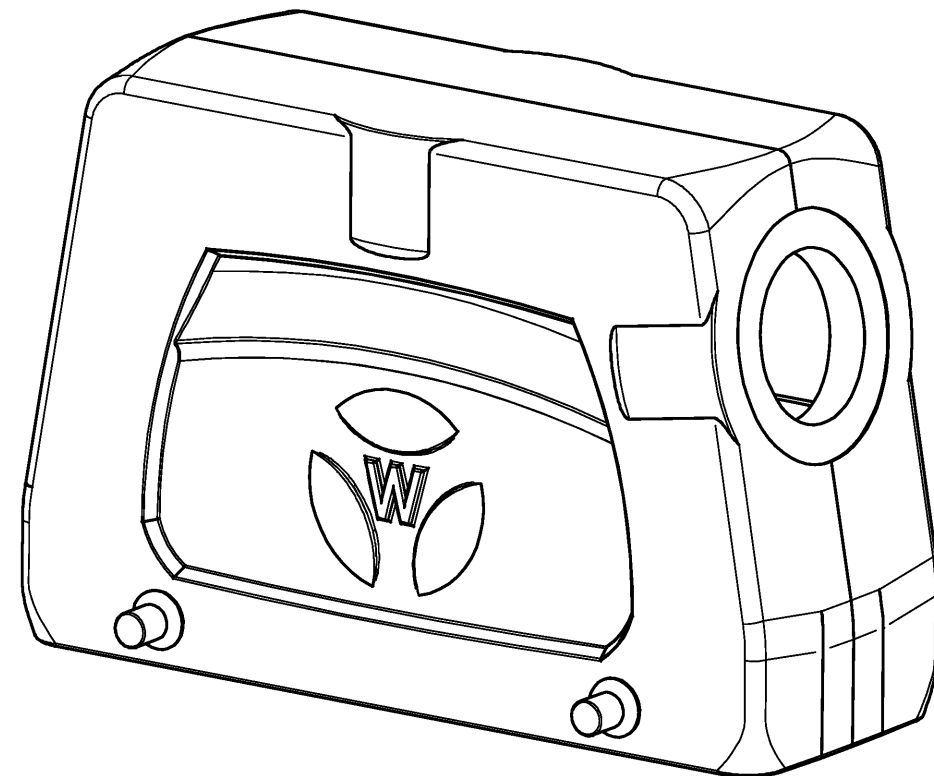

.0 .2 .3 .4 .5

Tolerierung Size ISO 14405 ☺ / Tolerance system Size ISO 14405 ☺ (This ISO-standard describes the envelope principle. According to the envelope principle the deviations of form and parallelism are limited by the size tolerances).					ja/yes ☑ Stoffverbots- und Deklarationsliste nach WN 5020.010 ist eingehalten. Conformity with Wieland document WN 5020.010 e (list of prohibited / declarable hazardous substances) to be declared!							
Freitoleranz nach General tolerance			CAD - Zeichnung, keine manuellen Änderungen CAD - drawing, no manual modifications allowed			1 Verwendung: First Use:		Blatt: 1 von 1 Sheet: of 1				
	/		Werkstoff / Material Aluminium beschichtet/coated grau/grey		Tag/Date	Name	T	Zeichnung Nr. / Drawing No. 73.350.6435.0 13K		Index		
	/				gezeichnet drawn	04.06.2014					Treschan	
	/				Maßstab / Scale	geprüft checked						
	/				1:1	Normgepr. Stand. check						
	/	Vol.	mm³	Dfl./Srf.	mm²	Ersatz für / Replacement for:						
	/	 wieland www.wieland-electric.com			Type	Benennung/Title						
	/				Index	Datum / Blatt Date / Sheet	Änderung / Revision	revos BASIC	GEHAEUSEOBERTEIL Baugröße 24H-Kabelabgang 1x M25/M32/M40 seitli8ch Hood size 24H-cable outlet 1x M25/M32/M40 side			
	/											
	/											