


Data sheet

Commercial Art.No.: Z5.531.3225.0

PCB pin header 8543... /2 D1.0/1.0

PCB pin header, 2 poles, pitch: 3.5 mm, type of packing: carton, color:grey

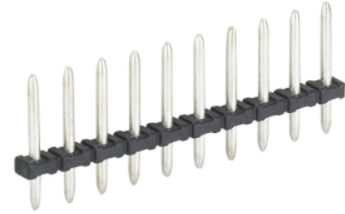

Certificates / Approvals



Technical data

General

Modular spacing	3.5 mm
Soldering process	Wave soldering
Packaging	Carton
Number of poles	2
Number of levels	1
Marking	No
Fastening	None
Mating direction towards (circuit) board	90°

Technical data

Rated current	6 A
Overvoltage Category I	690 V
Overvoltage Category II	250 V
Overvoltage Category III	160
Rated impulse voltage	2.5 kV

Technical Data UL/CSA

Voltage UL	300 V
Current field wiring	10 A
Current factory wiring	10 A
Voltage CSA	300 V
Current CSA	10 A

Other

Type of insulation material	Thermoplastic
Color	black
Height	13 mm
Length	7 mm
Depth	2.7 mm
Material contact base	CuZn

Material contact surface	Sn
--------------------------	----



Classification

ECLASS 11	
ECLASS 8.1	27440402
ETIM 7.0	EC002637
ETIM 6.0	EC002637
ETIM 5.0	EC002637
ETIM 4.0	EC002637

Product compliance

ROHS conformity status	Compliant
REACH-SVHC conformity status	Compliant

für folgende Tabellen-Zchnng.
Z5.531.5425.0 für 8543

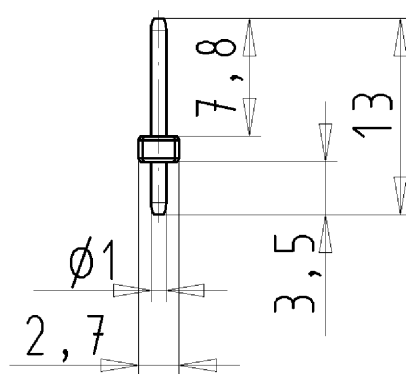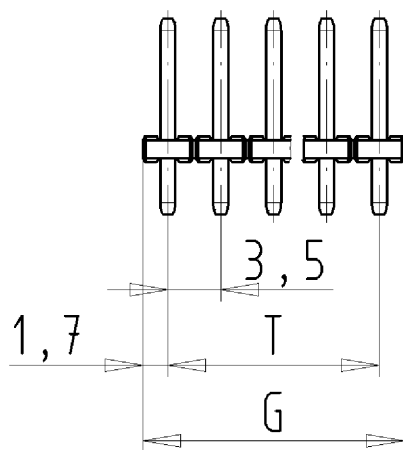

LP.STIFTLEISTE
Z5.531.3225.0 10W
31.10.2007 DÜT
M 2:1