
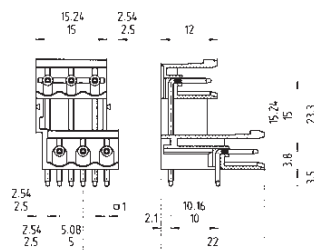


# Two-tier insulated headers for PC boards

## Spacings: 5.00/5.08 mm

Rated current:  
10 A

250 V/4 kV/3 – Overvoltage category III  
400 V/4 kV/2 – Overvoltage category II  
1000 V/4 kV/1 – Overvoltage category I

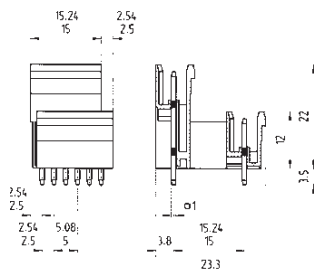

Solder pin 1 x 1 mm  
Bore hole Ø 1.4 mm



Solder pin 1 x 1 mm  
Bore hole Ø 1.4 mm

### Type 8113 SE/... G, 8213 SE/... G

vertical mount

### Type 8113 SE/... W, 8213 SE/... W

horizontal mount

Rated voltages: VDE 0110  
UL ratings  
CSA ratings  
Approvals

300 V 15 A  
300 V 10 A

300 V 15 A  
300 V 10 A



Std. pack	T	Poles	Part no.	Part no.	Part no.	Part no.
<b>Spacing: 5.00 mm</b>						
100	5	2 x 2	unmarked		unmarked	
100	10	2 x 3	25.334.3253.0		25.336.3253.0	
			25.334.3353.0		25.336.3353.0	
Slide together for larger pole configurations. Factory assembly available.						
<b>Spacing: 5.08 mm</b>						
100	5.08	2 x 2	unmarked		unmarked	
100	10.16	2 x 3	25.354.3253.0		25.356.3253.0	
			25.354.3353.0		25.356.3353.0	
Slide together for larger pole configurations. Factory assembly available.						
<b>Accessories:</b>						
End plate	50		07.310.9853.0		07.310.9853.0	
Fixing device assembly - for screw flanges on both sides of the header			upon request		only together with end plate 07.310.9853.0	Z5.523.2453.0

