


wiecon

 

Rated cross section:
2.5 mm²

Rated current:
12 A
related to 20 °C ambient temperature,
rated cross section and max. pole configuration

Connection range:
0.5 – 2.5 mm² solid / fine stranded

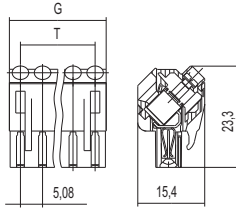

250 V/4 kV/3 – Overvoltage category III
400 V/4 kV/2 – Overvoltage category II
400 V/4 kV/1 – Overvoltage category I

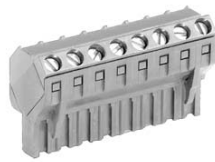

Type 8213 B/...S

Rated voltages: VDE 0110/1.89
UL ratings
CSA ratings
Approvals

No. 28 – 12 AWG
No. 28 – 12 AWG

300 V 10 A
300 V 10 A



Std. pack	GFL	G	T	Poles	Part no.	Part no.
Spacing: 5.08 mm						
100	10.16	5.08	2	27.341.3253.0		
100	15.24	10.16	3	27.341.3353.0		
50	20.32	15.24	4	27.341.3453.0		
50	25.40	20.32	5	27.341.3553.0		
50	30.48	25.40	6	27.341.3653.0		
50	35.56	30.48	7	27.341.3753.0		
50	40.64	35.56	8	27.341.3853.0		
50	45.72	40.64	9	27.341.3953.0		
50	50.80	45.72	10	27.341.4053.0		
50	55.88	50.80	11	27.341.4153.0		
50	60.96	55.88	12	27.341.4253.0		
50	66.04	60.96	13	27.341.4353.0		
50	71.12	66.04	14	27.341.4453.0		
50	76.20	71.12	15	27.341.4553.0		
50	81.28	76.20	16	27.341.4653.0		
					17 to 24pole upon request	
Coding available upon request						

